

Split shaft collar with clamp lever

BAG-MI

Steel

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:

Burnished steel (S250Pb)

Repeated operations

 



Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

Info.

- Recommended shaft tolerance: h11

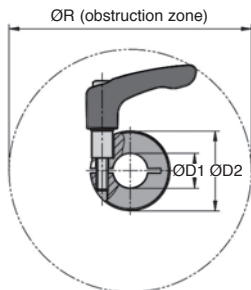

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI	10	24	9	44,1	-	14,83 €
BAG1-012-MI	12	28	11	90,4	✓	15,16 €
BAG1-015-MI	15	34	13	105,0	-	16,38 €
BAG1-016-MI	16	34	13	105,0	✓	16,73 €
BAG1-018-MI	18	36	13	105,7	-	17,46 €
BAG1-020-MI	20	40	15	103,8	✓	18,26 €
BAG1-022-MI	22	42	15	104,2	-	18,26 €
BAG1-025-MI	25	45	15	104,8	✓	19,34 €
BAG1-028-MI	28	48	15	106,8	-	19,34 €
BAG1-030-MI	30	54	15	112,6	✓	22,20 €
BAG1-040-MI	40	60	15	113,2	-	25,18 €
BAG1-050-MI	50	78	19	150,2	-	46,79 €

Dimensions in mm

Our other products



SSDB
Stainless steel bevel gear, 2:1



PF20
Worm and wheel gear reducer, up to 5 Nm



GE_C
Spherical bushing, Hard chromium / PTFE



DOMI120
Domino 120 adjustable slide, Slide DOMILINE 120



HLA24
Right angle spiro bevel gearbox, Up to 78Nm



HLA19
Right angle spiro bevel gearbox, Up to 43Nm



AC156-157
Strike for toggle latch, 25.5mm



CLR
Straight clevis, Straight clevis for use with a male clevis



DOMI80
Accessories, Plate



METEB
Self-lubricating blanks, Bronze BP25



AXTR
Axle for tensioner pulley, Shaft



AT5-16ECO
AT type timing pulley, Economy range - AT5 aluminium

Complementary products



BAG-MISS
Split shaft collar with clamp lever, Stainless steel



BAG
Steel Clamping collar, Steel