

Split shaft collar with clamp lever

BAG-MI

Steel

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:

Burnished steel (S250Pb)

Repeated operations

 



Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

Info.

- Recommended shaft tolerance: h11

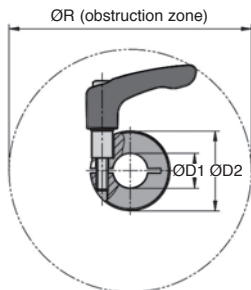

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI	10	24	9	44,1	-	14,83 €
BAG1-012-MI	12	28	11	90,4	✓	15,16 €
BAG1-015-MI	15	34	13	105,0	-	16,38 €
BAG1-016-MI	16	34	13	105,0	✓	16,73 €
BAG1-018-MI	18	36	13	105,7	-	17,46 €
BAG1-020-MI	20	40	15	103,8	✓	18,26 €
BAG1-022-MI	22	42	15	104,2	-	18,26 €
BAG1-025-MI	25	45	15	104,8	✓	19,34 €
BAG1-028-MI	28	48	15	106,8	-	19,34 €
BAG1-030-MI	30	54	15	112,6	✓	22,20 €
BAG1-040-MI	40	60	15	113,2	-	25,18 €
BAG1-050-MI	50	78	19	150,2	-	46,79 €

Dimensions in mm

Our other products



BLHM70

Right angled gearbox,
up to 128 Nm



 
BEF

Bearing housing for
miniature ballscrew,
Bearing housing



PW_PWG2

Worm - precision
range, Stainless steel



M1

Worm and wheel set,
Machined plastic
(delrin)



gt64

Rotating bent lever,
Common applications



BLHT70

Right angled gearbox,
from 26 to 128 Nm



CHB

Double output shaft,
For CHB gearbox



DCG

Suction cup, 2.5
bellows, silicon



NPTF30

Spacer for tube
carrier, Fixing
accessory Ø14 to Ø20



AC156-157

Strike for toggle latch,
25.5mm



MEP

Revolving handle for
handwheel, Fixed



VTAP

Magnetic head screw,
With rubber coating
With rubber coating

Complementary products



BAG-MISS

Split shaft collar with
clamp lever, Stainless
steel



BAG

Steel Clamping collar,
Steel