

# Split shaft collar with clamp lever

Stainless steel

BAG-MI/SS

Repeated operations

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:  
Polished stainless steel (303)


## Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

## Info.

- Recommended shaft tolerance: h11

stainless steel

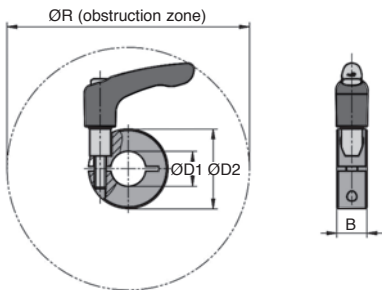

## DISCOUNTS

Qty	1+	6+	40+
Disc.	List	-15%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI/SS	10	24	9	44,1	✓	21,60 €
BAG1-012-MI/SS	12	28	11	90,4	-	21,93 €
BAG1-015-MI/SS	15	34	13	105,0	✓	25,63 €
BAG1-016-MI/SS	16	34	13	105,0	✓	25,91 €
BAG1-018-MI/SS	18	36	13	105,7	-	28,61 €
BAG1-020-MI/SS	20	40	15	103,8	✓	33,16 €
BAG1-022-MI/SS	22	42	15	104,2	-	34,05 €
BAG1-025-MI/SS	25	45	15	104,8	✓	34,95 €
BAG1-028-MI/SS	28	48	15	106,8	-	36,74 €
BAG1-030-MI/SS	30	54	15	112,6	✓	38,53 €
BAG1-040-MI/SS	40	60	15	113,2	✓	53,49 €
BAG1-050-MI/SS	50	78	19	150,2	-	106,10 €

Dimensions in mm

0 825 88 6000

Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

113

## Our other products



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



GGP

Male wing knob, Technopolymer with brass spindle



MHX

Hexagonal threaded sleeve, Hexagonal - steel




PDM\_PDV

Detectable plastic palm grip, blue thermoplastic



UGH40

H Type Guide units, For Ø40 actuators

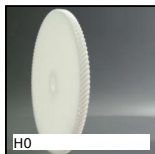

H0

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



CLM

Male clevis end, Stainless steel short



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



GMK17\_BROSSE

Brush strip, Cone-shaped - brush



G01

Single universal joint, Normal duty



E60B

Right angle helical reducers, from 4.50 to 24 Nm

## Complementary products



BAG-MI

Split shaft collar with clamp lever, Steel



BAGSS

Stainless steel Clamping collar, Stainless steel