

Split shaft collar with clamp lever

Stainless steel

BAG-MI/SS

Repeated operations

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:
Polished stainless steel (303)


Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

Info.

- Recommended shaft tolerance: h11

stainless steel

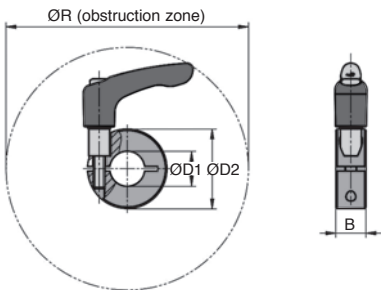

DISCOUNTS

Qty	1+	6+	40+
Disc.	List	-15%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI/SS	10	24	9	44,1	✓	21,60 €
BAG1-012-MI/SS	12	28	11	90,4	-	21,93 €
BAG1-015-MI/SS	15	34	13	105,0	✓	25,63 €
BAG1-016-MI/SS	16	34	13	105,0	✓	25,91 €
BAG1-018-MI/SS	18	36	13	105,7	-	28,61 €
BAG1-020-MI/SS	20	40	15	103,8	✓	33,16 €
BAG1-022-MI/SS	22	42	15	104,2	-	34,05 €
BAG1-025-MI/SS	25	45	15	104,8	✓	34,95 €
BAG1-028-MI/SS	28	48	15	106,8	-	36,74 €
BAG1-030-MI/SS	30	54	15	112,6	✓	38,53 €
BAG1-040-MI/SS	40	60	15	113,2	✓	53,49 €
BAG1-050-MI/SS	50	78	19	150,2	-	106,10 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com **HPC** SUPPLEMENT 2019

113

Our other products



SCH

Horizontal hook toggle clamp,
Horizontal Hook clamp - stainless steel




MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



ZDB

Machined plastic bevel gear , 2:1

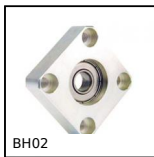

BH02

Single housed bearing assembly, Bearing secured with circlips



DOMI30

Accessories, Plate



FF15

Offset spur gear reducer, from 2.20 to 10 Nm



D19 D29

Compression springs in metre length stainless steel, by the metre



SLVVlok

Vertical toggle clamp, Vertical toggle clamp / vertical foot



SDA

Locking bolt support bracket, Mounting



BTC_M

End cap with threaded insert for square tube,



CAP881

Side flexing slim slat top chain stainless



DOMI50

Accessories, Plate

Complementary products



BAG-MI

Split shaft collar with clamp lever, Steel



BAGSS

Stainless steel Clamping collar,
Stainless steel