

# SteStaNew Locking rings in steel or stainless steel

Conforms to DIN705, solid

**BAG0**

- Cylindrical locking ring conforming to DIN705
- Secured using a set screw (DIN914)
- Materials:  
Steel, natural finish  
303 stainless steel, natural finish

**NEW!**




## Advantages

- Allows a stop or an axial block to be quickly added to a shaft

## Info

- Alternative bores available

Lowest price available!

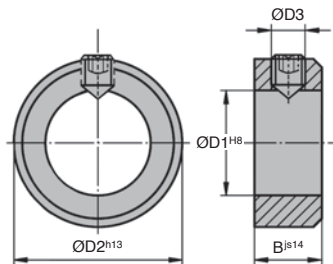

## DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc	List	-6%	-12%	-18%	On request

Part number		ØD1	B	ØD2	ØD3	Weight (kg)	Price each 1 to 4	
Steel	S/steel						Steel	S/steel
BAG0-006	BAG0-006/SS	6	8	12	M4x5	0,005	0,78 €	1,87 €
BAG0-008	BAG0-008/SS	8	8	16	M4x6	0,009	0,86 €	2,25 €
BAG0-010	BAG0-010/SS	10	10	20	M5x8	0,018	1,14 €	2,74 €
BAG0-012	BAG0-012/SS	12	12	22	M6x8	0,025	1,27 €	3,61 €
BAG0-015	BAG0-015/SS	15	12	25	M6x8	0,03	1,41 €	4,10 €
BAG0-016	BAG0-016/SS	16	12	28	M6x8	0,039	1,49 €	5,77 €
BAG0-020	BAG0-020/SS	20	14	32	M6x8	0,054	1,90 €	7,50 €
BAG0-025	BAG0-025/SS	25	16	40	M8x10	0,096	2,88 €	12,40 €
BAG0-030	BAG0-030/SS	30	16	45	M8x10	0,111	3,78 €	14,58 €
BAG0-035	BAG0-035/SS	35	16	56	M8x12	0,189	5,11 €	23,22 €
BAG0-040	BAG0-040/SS	40	18	63	M10x16	0,263	7,45 €	30,70 €
BAG0-050	BAG0-050/SS	50	18	80	M10x16	0,433	11,14 €	44,98 €

Dimensions in mm

## Our other products



MHMEP

Arm with rotating handle, Prebored



TCL-ECL

Support rod for heavy loads, Support spindle



PW\_PWG05

Wheel - precision range, Bronze



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze



LINK64

Synchronous AC Motor and-gearbox , from 1.3 to 6Nm



PRF\_CH

Cable-carrier chain for aluminium profile, Supplied in metre lengths



PHTss

Pull handle, Up to 250 °C



CHM75

Worm and wheel gear reducer, up to 298 Nm



EAR

Bearing locknut, Self locking locknut - nylon lock washer



GG1

Ground spur gear, Heat treated steel



CHAPAM

Weld-on hinge with flat end, Steel



HCSS

Set screw with hexagonal socket, Cup point

## Complementary products



BAGSS

Stainless steel Clamping collar, Stainless steel