

SteStaNew Locking rings in steel or stainless steel

Conforms to DIN705, solid

BAG0

- Cylindrical locking ring conforming to DIN705
- Secured using a set screw (DIN914)
- Materials:
Steel, natural finish
303 stainless steel, natural finish

NEW!




Advantages

- Allows a stop or an axial block to be quickly added to a shaft

Info

- Alternative bores available

Lowest price available!

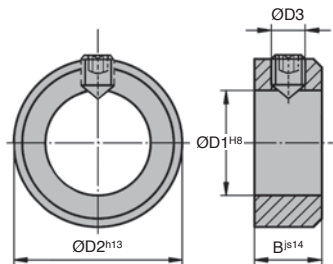

DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc	List	-6%	-12%	-18%	On request

Part number		ØD1	B	ØD2	ØD3	Weight (kg)	Price each 1 to 4	
Steel	S/steel						Steel	S/steel
BAG0-006	BAG0-006/SS	6	8	12	M4x5	0,005	0,78 €	1,87 €
BAG0-008	BAG0-008/SS	8	8	16	M4x6	0,009	0,86 €	2,25 €
BAG0-010	BAG0-010/SS	10	10	20	M5x8	0,018	1,14 €	2,74 €
BAG0-012	BAG0-012/SS	12	12	22	M6x8	0,025	1,27 €	3,61 €
BAG0-015	BAG0-015/SS	15	12	25	M6x8	0,03	1,41 €	4,10 €
BAG0-016	BAG0-016/SS	16	12	28	M6x8	0,039	1,49 €	5,77 €
BAG0-020	BAG0-020/SS	20	14	32	M6x8	0,054	1,90 €	7,50 €
BAG0-025	BAG0-025/SS	25	16	40	M8x10	0,096	2,88 €	12,40 €
BAG0-030	BAG0-030/SS	30	16	45	M8x10	0,111	3,78 €	14,58 €
BAG0-035	BAG0-035/SS	35	16	56	M8x12	0,189	5,11 €	23,22 €
BAG0-040	BAG0-040/SS	40	18	63	M10x16	0,263	7,45 €	30,70 €
BAG0-050	BAG0-050/SS	50	18	80	M10x16	0,433	11,14 €	44,98 €

Dimensions in mm

Our other products



E40

Right angle helical reducers, from 2.30 to 20 Nm



CHAu

Screwed hinge, 270°



GP

Spring loaded toggle latch, Standard (GP22-GP23)



SLB

Indexing plunger, stainless steel



FF30

Offset spur gear reducer, from 21.50 to 83 Nm



CHAFR

Adjustable friction hinges, Friction



DER63

Stainless steel AC asynchronous motor 0.18 kW, 0.18kW



PDD

Spring plunger, With sensor adaptor



LVT

Miniature motorised actuator 4A, 4 amperes



PMC150_M16

Anti-vibration machine mount,



CHAC4040NP

Square hinge with riveted pin, not



TOC

Short swivel head, Short

Complementary products



BAGSS

Stainless steel Clamping collar, Stainless steel