

Lead screw locking ring

Single piece assembly

BAGTR

- Single piece lead screw locking assembly


- Material:
Anodised aluminium

Accessory


- LFM leadscrew

Info

- Screw head can be larger than diameter $\varnothing D$
- Overall dimension is $\varnothing D + 2$ mm

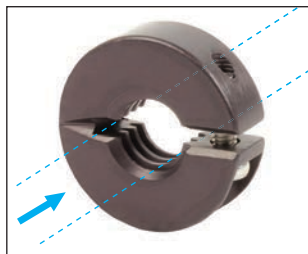

Typical application:
fitted to a LFM lead screw

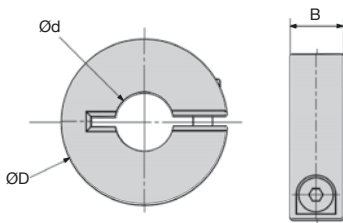

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-10%	-18%	On request

Part number	$\varnothing d$	$\varnothing D$	B	Static axial load	Price each 1 to 9
Right handed thread					
BAG1-TR10	TR10X2	24	8	1800	13,01 €
BAG1-TR12	TR12X3	28	8	2096	23,91 €
BAG1-TR16	TR16X4	34	11	3840	18,71 €
BAG1-TR18	TR18X4	36	13	5216	18,94 €
BAG1-TR20	TR20X4	45	15	6784	19,77 €
BAG1-TR24	TR24X5	45	15	8096	33,23 €
Left handed thread					
BAG1-TR10/LH	TR10X2	24	8	1800	14,96 €
BAG1-TR12/LH	TR12X3	28	8	2096	27,48 €
BAG1-TR16/LH	TR16X4	34	11	3840	21,52 €
BAG1-TR18/LH	TR18X4	36	13	5216	21,79 €
BAG1-TR20/LH	TR20X4	45	15	6784	22,72 €
BAG1-TR24/LH	TR24X5	45	15	8096	38,21 €

Dimensions in mm

Our other products



DZYSS

Stainless steel cylindrical stop, stainless steel



BLH20

Right angled gearbox, from 0.53 to 1.77



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW



RFK28B

Hypoid gearbox - Stainless steel, up to 130 Nm



CABtool

Fitting cable tools, Cutting tools



WW20

Drylin® W slide, slide assembly



VDSQCB

Sliding lock adjustment system, Blocking wedge



CFS

Miniature cam follower, Miniature



PHG05

Parallel axis helical gear - Precision range, 20NCD2 case



NCT

Square tube connector, Fixed angle



PCF4

Conical flexible mount, Square base plate



PT820

Drive sprocket for slat top chain, Ranges 820 and 815

Complementary products



LFM

Steel leadscrew, Medium carbon steel - 1 thread