

Lead screw locking ring

Single piece assembly

BAGTR

- Single piece lead screw locking assembly


- Material:
Anodised aluminium

Accessory


- LFM leadscrew

Info

- Screw head can be larger than diameter $\varnothing D$
- Overall dimension is $\varnothing D + 2$ mm

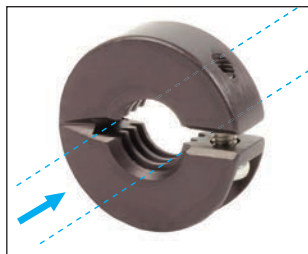

Typical application:
fitted to a LFM lead screw

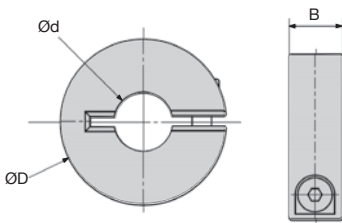

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-10%	-18%	On request

Part number	$\varnothing d$	$\varnothing D$	B	Static axial load	Price each 1 to 9
Right handed thread					
BAG1-TR10	TR10X2	24	8	1800	13,01 €
BAG1-TR12	TR12X3	28	8	2096	23,91 €
BAG1-TR16	TR16X4	34	11	3840	18,71 €
BAG1-TR18	TR18X4	36	13	5216	18,94 €
BAG1-TR20	TR20X4	45	15	6784	19,77 €
BAG1-TR24	TR24X5	45	15	8096	33,23 €
Left handed thread					
BAG1-TR10/LH	TR10X2	24	8	1800	14,96 €
BAG1-TR12/LH	TR12X3	28	8	2096	27,48 €
BAG1-TR16/LH	TR16X4	34	11	3840	21,52 €
BAG1-TR18/LH	TR18X4	36	13	5216	21,79 €
BAG1-TR20/LH	TR20X4	45	15	6784	22,72 €
BAG1-TR24/LH	TR24X5	45	15	8096	38,21 €

Dimensions in mm

Our other products



BOX-CSss

Hose clamp, Box set of stainless steel hose clamps



YG0

HEAVY DUTY spur gear, Steel 35NCD6



T10_30_AL

T type timing pulley, Economy range - T10 aluminium



SLV

Vertical toggle clamp, Vertical Lever Clamp - stainless steel



PRFSRAD

Dual lock for aluminium profile, Quick fitting, self locking door du...



TBL

Mini leadscrew table with metric thread, 1kg



SME

Male rod ends , Stainless steel / PTFE



BAGtr

Lead screw clamping collar, Aluminium




DBL880

Idler for slat top chain, Ranges 880 and 881



HBM

 Adjustment bushing for half-rail guide, Adjustment bushing



BMF

Knurled knob - female, Knurled - through threaded



CHINV

Invisible hinge, Invisible - Opening up to 90°

Complementary products



LFM

Steel leadscrew, Medium carbon steel - 1 thread