

Angular clamp



BAN

For profile systems



- Easy to add to most profiles
- Material :
Aluminium
- Fixing kit not supplied

Advantages


- Wide range of assembly possibilities
- **Angular clamp** : space saving when assembling compact
- **Universal angular clamp** : Compatible with 20mm and 300 mm profile systems with oblong holes
- **Adjustable angular clamp** : Flexible positioning of gripping elements due to use of rectangular holes

Accessories


- PRF-ECLM8 nut
- M8 screw, length 20-22mm

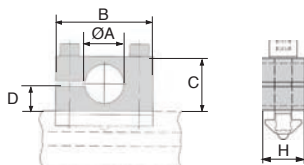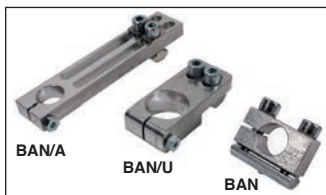

Angular clamp

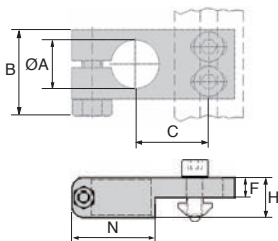

Universal angular clamp

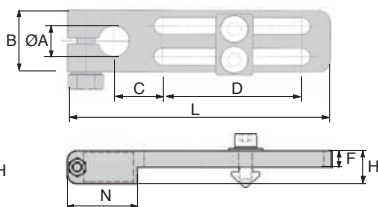

Adjustable angular clamp

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 10+ | 30+ |
| Disc. | List | -5% | On request |

| Part number | Type | ØA | B | C | D | L | H | F | N | Weight (g) | Price each 1 to 9 |
|-------------|------------|----|----|-------|-----|-----|------|----|----|------------|-------------------|
| BAN-20 | - | 20 | 45 | 24,5 | 12 | - | 20 | - | - | 103 | 28,20 € |
| BAN-30 | - | 30 | 68 | 34 | 17 | - | 20 | - | - | 172 | 33,25 € |
| BAN-20/U | universal | 20 | 30 | 32-42 | - | - | 20 | 10 | 33 | 114 | 28,19 € |
| BAN-30/U | universal | 30 | 35 | 37-47 | - | - | 20 | 10 | 42 | 122 | 34,56 € |
| BAN-20/A | adjustable | 20 | 30 | 21 | 100 | 130 | 12,5 | - | - | 140 | 34,75 € |
| BAN-30/A | adjustable | 30 | 35 | 25,5 | 100 | 159 | 20 | 10 | 42 | 213 | 40,44 € |

Dimensions in mm

Our other products



BSP

Compact precision slide, from 156 N to 980 N




PTA40

Articulated foot with solid base foot \varnothing 40, 3000N



DBL821

Idler for slat top chain, Range 821

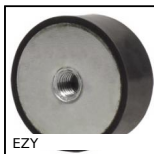

EZY

Cylindrical stop, Steel



PRF_PL_4590

Joining plate for aluminium profile, joint plate - 45x90 mm



BPVM

Miniature ball transfer unit, Miniature to screw




ASH

Hoist ring for welding, for straight lifts - for welding



CHA35

 Hinge for aluminium profile, Hinge



RPP3

RPP heavy duty timing belt, RPP3



GGP

Male wing knob, Technopolymer with brass spindle



RPCtc

Swivel castor with central hole, Steel - Polyamide



PP50

Worm and wheel gear reducer, from 6.50 to 12.80 Nm

Complementary products



BAN

Angular clamp, Standard



PRF_ECL

Nut for aluminium profile, Steel square nut with tab