

Angular clamp



BAN

For profile systems



- Easy to add to most profiles
- Material :
Aluminium
- Fixing kit not supplied

Advantages


- Wide range of assembly possibilities
- **Angular clamp** : space saving when assembling compact
- **Universal angular clamp** : Compatible with 20mm and 300 mm profile systems with oblong holes
- **Adjustable angular clamp** : Flexible positioning of gripping elements due to use of rectangular holes

Accessories


- PRF-ECLM8 nut
- M8 screw, length 20-22mm

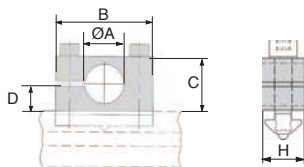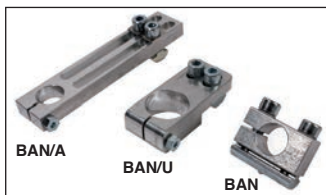

Angular clamp

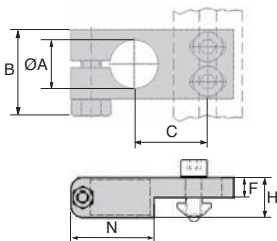

Universal angular clamp

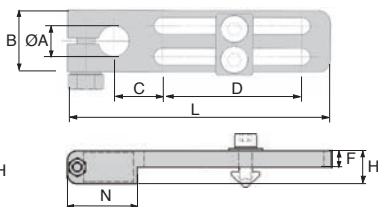

Adjustable angular clamp


DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	ØA	B	C	D	L	H	F	N	Weight (g)	Price each 1 to 9
BAN-20	-	20	45	24,5	12	-	20	-	-	103	28,20 €
BAN-30	-	30	68	34	17	-	20	-	-	172	33,25 €
BAN-20/U	universal	20	30	32-42	-	-	20	10	33	114	28,19 €
BAN-30/U	universal	30	35	37-47	-	-	20	10	42	122	34,56 €
BAN-20/A	adjustable	20	30	21	100	130	12,5	-	-	140	34,75 €
BAN-30/A	adjustable	30	35	25,5	100	159	20	10	42	213	40,44 €

Dimensions in mm

 Our other products



LRH

Bi-directional leadscrew, Bi-directional - 1 thread



STL

Guidance brush - Rail, Rail



CABma

Swaging sleeve for fitting cable, To crimp a wire rope



PPOss

Pad eye on mounting plate oval, Stainless steel



PRF-CHAR-POU

Tool holder for aluminium profile, Moveable tool holder



 
LRRA

Latch with locking system, Aluminium



GLB

Small 6 lobe threaded handle - female, Technopolymer - Stainless steel



GE

Toggle latches, Standard



CFUURSS

Cam follower stainless steel, Standard - stainless steel



SVR15

Screwjack with travelling nut, with moving nut



G-ECO

Eco range Spur gear, Steel C45



BLM

Spring loaded plunger with ball tip, Plastic body

Complementary products



BAN

Angular clamp, Universal



PRF_ECL

Nut for aluminium profile, Steel square nut with tab