

# Angular clamp



## BAN

## For profile systems



- Easy to add to most profiles
- Material :  
Aluminium
- Fixing kit not supplied

### Advantages


- Wide range of assembly possibilities
- **Angular clamp** : space saving when assembling compact
- **Universal angular clamp** : Compatible with 20mm and 300 mm profile systems with oblong holes
- **Adjustable angular clamp** : Flexible positioning of gripping elements due to use of rectangular holes

### Accessories


- PRF-ECLM8 nut
- M8 screw, length 20-22mm

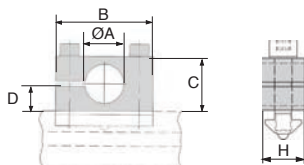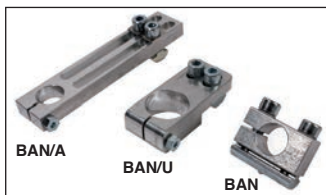

Angular clamp

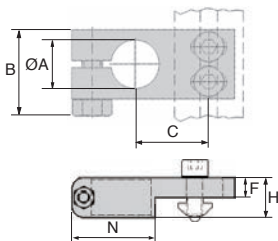

Universal angular clamp

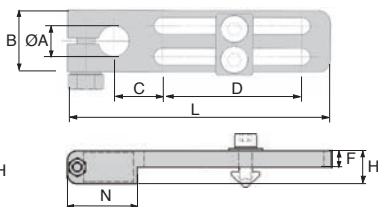

Adjustable angular clamp

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	Type	ØA	B	C	D	L	H	F	N	Weight (g)	Price each 1 to 9
BAN-20	-	20	45	24,5	12	-	20	-	-	103	28,20 €
BAN-30	-	30	68	34	17	-	20	-	-	172	33,25 €
BAN-20/U	universal	20	30	32-42	-	-	20	10	33	114	28,19 €
BAN-30/U	universal	30	35	37-47	-	-	20	10	42	122	34,56 €
BAN-20/A	adjustable	20	30	21	100	130	12,5	-	-	140	34,75 €
BAN-30/A	adjustable	30	35	25,5	100	159	20	10	42	213	40,44 €

Dimensions in mm

## Our other products



PRF\_ER  
Joining bar for aluminium profile, Joint bar



CHMR30  
Worm and wheel gear reducer, up to 28 Nm



ADL\_F  
Female eye bolt conforms to DIN582, Stainless steel



VLBS  
Folding lifting ring for welding, Folding - for welding



AC156-157  
Strike for toggle latch, 25.5mm



BPHT  
Ball transfer unit bolt fitting, Heavy



BUT  
Panel stop, Panel stop



NT122  
Spur gear coaxial gearbox, from 32 to 85 Nm - Inline



MSP38  
Masterplate® glueable insert Ø38, 5mm hole



BSM  
Spring plunger with internal hexagonal



WBGV  
Lifting ring, Threaded



ZBconique  
Machined plastic bevel gear, 1:1

## Complementary products



BAN  
Angular clamp, Standard



PRF\_ECL  
Nut for aluminium profile, Steel square nut with tab