

Clamping collar



BAP






Ø10 to Ø20

- 2 part clamping collar

- Materials:

Body: reinforced polyamide

Screws: stainless steel 304

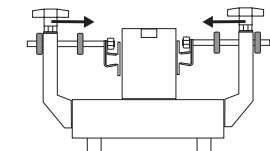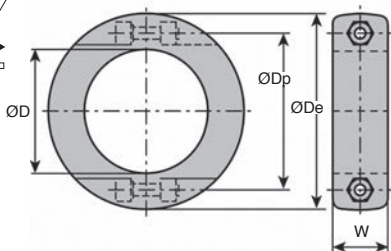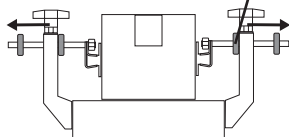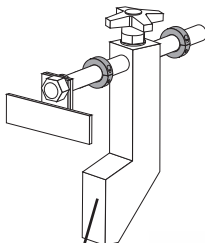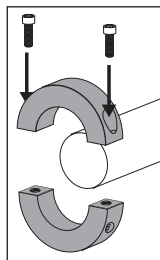

DISCOUNTS

Qty	1+	40+	100+	200+	300+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	ØDe	ØDp	W	Weight (kg)	Stock*	Price each 1 to 39
BAP-10	10	30	20	12	0,01	✓	3,15 €
BAP-12	12	30	20	12	0,01	✓	3,15 €
BAP-14	14	30	20	12	0,01	✓	3,15 €
BAP-15	15	39	27	14	0,02	✓	3,15 €
BAP-16	16	39	27	14	0,02	✓	3,15 €
BAP-18	18	39	27	14	0,02	✓	3,15 €
BAP-20	20	40	29	14	0,02	✓	3,15 €

*Depending on availability - Dimensions in mm

Our other products



G1

Steel spur gear, Steel 20NCD2



SSDB

Stainless steel bevel gear, 2:1



EKN

Bellows coupling Gerwah®, from 0.5 to 12Nm



GG1

Ground spur gear, Heat treated steel



EAR

Bearing locknut, Self locking locknut - nylon lock washer



ACLEPP

Right angled bracket for aluminium profile, 4 holes



BPPL

Assembly tool for carrier ball, Mounting tool



CHM90

Worm and wheel gear reducer, up to 540 Nm



ES

Bipod support base, Plastic



PGT

Sliding profile, Sliding panel support



NCT

Square tube connector, Fixed



GB-RA

Brass spur gear, Brass CuZn39Pb3

Complementary products



BAP25

Plastic clamping collar, Ø25 - Ø40



BAG

Steel Clamping collar, Steel



BAGSS

Stainless steel Clamping collar, Stainless steel



PR820

Idler sprocket for slat top chain, Rangs 820 and 815