

Clamping collar



BAP






Ø10 to Ø20

- 2 part clamping collar

- Materials:

Body: reinforced polyamide

Screws: stainless steel 304

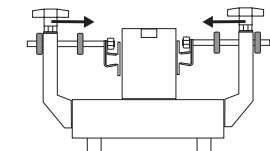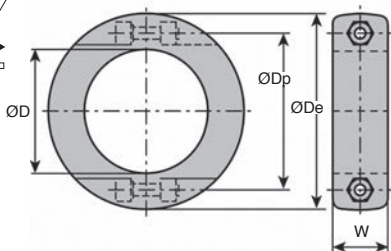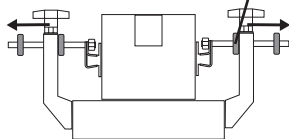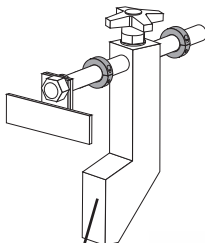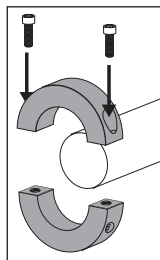

DISCOUNTS

Qty	1+	40+	100+	200+	300+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	ØDe	ØDp	W	Weight (kg)	Stock*	Price each 1 to 39
BAP-10	10	30	20	12	0,01	✓	3,15 €
BAP-12	12	30	20	12	0,01	✓	3,15 €
BAP-14	14	30	20	12	0,01	✓	3,15 €
BAP-15	15	39	27	14	0,02	✓	3,15 €
BAP-16	16	39	27	14	0,02	✓	3,15 €
BAP-18	18	39	27	14	0,02	✓	3,15 €
BAP-20	20	40	29	14	0,02	✓	3,15 €

*Depending on availability - Dimensions in mm

Our other products



LRR-53

Spring loaded latch,
Spring return latch -
stainless steel



FF30

Offset spur gear
reducer, from 21.50
to 83 Nm



T2

T type timing belt,
T2.5 Steel cored,
polyurethane



RCC_RCX

Spherical tilt washer -
DIN6319, concave



HG8-ECO

Eco range Spur gear,
Steel C45



DGSA

Male rod ends , Steel /
steel - Economy range



GE

Toggle latches,
Miniature



HCSS

Set screw with
hexagonal socket,
Cup point



BLM

Spring loaded plunger
with ball tip, Stainless
steel body



PRF-GPB

Guide for aluminium
profile, Rail for 8mm
wide slots



NCT

Square tube
connector, Fixed
angle



PRS80

Stainless steel
articulated foot Ø80,
Ø 80

Complementary products



BAP25

Plastic clamping
collar, Ø25 - Ø40



BAG

Steel Clamping collar,
Steel



BAGSS

Stainless steel
Clamping collar,
Stainless steel



PR820

Idle sprocket for slat
top chain, Rangs 820
and 815