

# Clamping collar



## BAP






## Ø10 to Ø20

- 2 part clamping collar

- Materials:

Body: reinforced polyamide

Screws: stainless steel 304

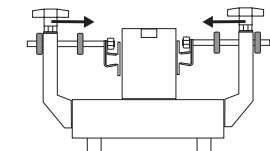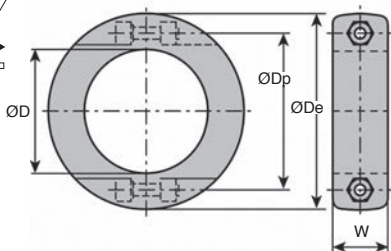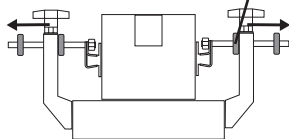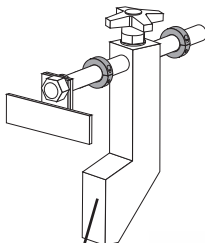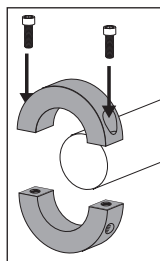

### DISCOUNTS

Qty	1+	40+	100+	200+	300+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	ØDe	ØDp	W	Weight (kg)	Stock*	Price each 1 to 39
BAP-10	10	30	20	12	0,01	✓	3,15 €
BAP-12	12	30	20	12	0,01	✓	3,15 €
BAP-14	14	30	20	12	0,01	✓	3,15 €
BAP-15	15	39	27	14	0,02	✓	3,15 €
BAP-16	16	39	27	14	0,02	✓	3,15 €
BAP-18	18	39	27	14	0,02	✓	3,15 €
BAP-20	20	40	29	14	0,02	✓	3,15 €

\*Depending on availability - Dimensions in mm

## Our other products



CDPC  
Flanged drill bushing,  
Steel



 
P60  
Worm and wheel gear  
reducer, up to 118  
Nm



BPM  
Slotted spring plunger  
with ball tip, Stainless  
steel 303



BAGO  
Locking rings in steel,  
Steel



MR\_MMR  
Metric section rack,  
Steel



GAL21  
Conveyor wheel,  
Plastic



PCH  
Knob for gripping,  
Mushroom



DB  
Steel bevel gear, 2:1



SUPCC  
Self-centering  
clamping hub steel,  
With lock nut



SLB  
Indexing plunger,  
steel class 5.8



CHN\_CHNSS  
Straight long link  
stainless steel chain,  
Stainless steel



BOX-TOR-INCH  
Box set of Nitrile O-  
rings in inch NBR90Sh  
A, For fasteners and  
fit...

## Complementary products



BAP25  
Plastic clamping  
collar, Ø25 - Ø40



BAG  
Steel Clamping collar,  
Steel



BAGSS  
Stainless steel  
Clamping collar,  
Stainless steel



PR820  
Idler sprocket for slat  
top chain, Rangs 820  
and 815