

Clamping collar



BAP






Ø10 to Ø20

- 2 part clamping collar

- Materials:

Body: reinforced polyamide

Screws: stainless steel 304

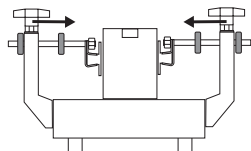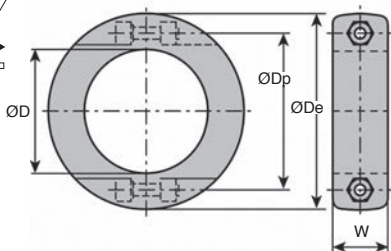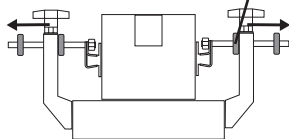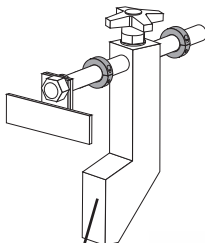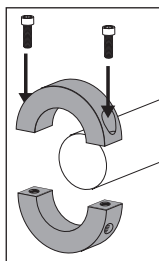

DISCOUNTS

Qty	1+	40+	100+	200+	300+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	ØDe	ØDp	W	Weight (kg)	Stock*	Price each 1 to 39
BAP-10	10	30	20	12	0,01	✓	3,15 €
BAP-12	12	30	20	12	0,01	✓	3,15 €
BAP-14	14	30	20	12	0,01	✓	3,15 €
BAP-15	15	39	27	14	0,02	✓	3,15 €
BAP-16	16	39	27	14	0,02	✓	3,15 €
BAP-18	18	39	27	14	0,02	✓	3,15 €
BAP-20	20	40	29	14	0,02	✓	3,15 €

*Depending on availability - Dimensions in mm

Our other products



RFKfp
Stainless steel
gearbox - accessories,
Mounting bracket



PRF_GAL
Roller for aluminium
profile, Fixing kit for
roller concentric



SLB
Indexing plunger,
steel class 5.8



GP75
Spring loaded toggle
latch, Standard
(GP75)



T5courroie
T type timing belt, T5
Steel cored
polyurethane



SRG
Adjustable latch
clamp with strike
plate, Stroke from
77,3mm to 83mm



SER
Magnetic doorstop for
aluminium profile,
Magnetic doorstop



VHTM
Hexagonal headed
screw Hygienic
Design®, Stainless
steel



RDS
Safety washer
Hygienic Usit®,
Stainless steel



AT10-BAR
AT type tooth bar
stock, AT10



P55
Worm and wheel gear
reducer, up to 57 Nm



HBM
Adjustment bushing
for half-rail guide,
Adjustment bushing

Complementary products



BAP25
Plastic clamping
collar, Ø25 - Ø40



BAG
Steel Clamping collar,
Steel



BAGSS
Stainless steel
Clamping collar,
Stainless steel



PR820
Idler sprocket for slat
top chain, Rangs
820 and 815