



- Suitable for transmitting high torque values

- Material:

Steel C45

### Accessories

- Steel or stainless steel splined shaft

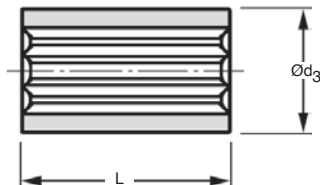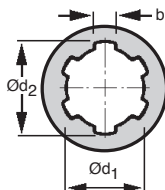


### DISCOUNTS

Qty	1+	10+	20+	30+	40+
Disc.	List	-15%	-20%	-30%	On request

Part number	Number of splines	$\varnothing d_1$	$\varnothing d_2$	b	L		$\varnothing d_3$	Stock*	Price each 1 to 9
					total length	splined length			
BCA6-14	6	11,00	14,00	3,00	40	30	25	✓	11,80 €
BCA6-16	6	13,00	16,00	3,50	40	40	28	✓	11,10 €
BCA6-20	6	16,00	20,00	4,00	50	50	30	✓	11,10 €
BCA6-22	6	18,00	22,00	5,00	50	50	32	✓	11,10 €
BCA6-25/40	6	21,00	25,00	5,00	40	40	38	✓	13,08 €
BCA6-25	6	21,00	25,00	5,00	60	60	38	✓	13,08 €
BCA6-28	6	23,00	28,00	6,00	60	60	38	✓	13,59 €
BCA6-32	6	26,00	32,00	6,00	60	60	42	✓	13,59 €
BCA6-34	6	28,00	34,00	7,00	60	60	45	✓	15,25 €
BCA8-38	8	32,00	38,00	6,00	60	60	55	✓	22,28 €
BCA8-42	8	36,00	42,00	7,00	70	70	60	✓	26,07 €
BCA8-48	8	42,00	48,00	8,00	70	70	65	✓	32,39 €
BCA8-54	8	46,00	54,00	9,00	80	80	70	✓	43,20 €

\*Depending on availability - Dimensions in mm
 
## Our other products



SLS

Bearing block for leadscrew, Fixed Drylin® bearing block



S2B

Short linear bearing housing, Closed - Slim



SH0

Parallel axis helical gear, Steel 20NCD2



MDB\_MTB

Moulded plastic bevel gear (nylon), 2:1



 
JSM

Cylindrical polymer bush, Universal polymer



HSSss

Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379



FTSN

Supported shaft for linear guide, Steel shaft / Aluminium support



PW\_PWG1

Worm - precision range, Steel



PRF-SCREEN-5

Screen support, Support with 5 axes of



LRR

Spring loaded latch, Spring loaded latch



HTD8M\_50

HTD Heavy duty timing pulley, HTD8



DOMI\_MD

Domino rotary table, 55/1

## Complementary products



ACA

Steel splined shaft, Steel



ACAss

Stainless steel splined shaft, Stainless steel