
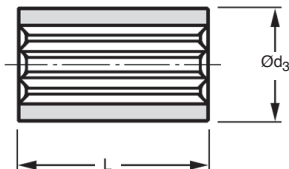


- Suitable for transmitting high torque values
- Materials:
Stainless steel 304

Accessories

- Stainless steel splined shaft ACAss

For hostile environments

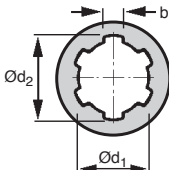

NEW!
Replace the part
number BUC00

DISCOUNTS

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	$\varnothing d_{1H7}$	$\varnothing d_2$	b^{D9}	L	$\varnothing d_3^{H11}$	Weight (kg)	Price each
BCA6-14/SS	6	11,00	14,00	3,00	25	18,75	0,028	27,87 €
BCA6-16/SS	6	13,00	16,00	3,50	30	21,75	0,047	32,74 €
BCA6-20/SS	6	16,00	20,00	4,00	30	28,50	0,090	36,40 €
BCA6-25/SS	6	21,00	25,00	5,00	40	36,00	0,190	51,48 €
BCA6-32/SS	6	26,00	32,00	6,00	40	42,50	0,242	66,26 €
BCA8-38/SS	8	32,00	38,00	6,00	40	49,70	0,304	77,37 €

Dimensions in mm

Our other products



PF30
Worm and wheel gear reducer, up to 8.80 Nm



UGH16
H Type Guide units, For Ø12 and Ø16 actuators




MDB_MTB
Moulded plastic bevel gear (nylon), 2:1



AZY
Cylindrical elasto mount, Steel



GARQT
Quarter turn lock pin for clamping, Quarter turn

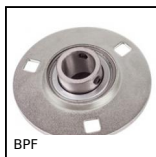

BPF
Sheet steel flanged bearing for light loads, Sheet steel



DKGS
Backlash free coupling Gerwah®, from 0.5 to 3Nm



GE14
Toggle latches, With padlock-holder



BAG-MISS
Split shaft collar with clamp lever, Stainless



PWC
Powercoil thread inserts, Kit Powercoil -



BG
Oldham coupling, With set screw



PITAss
Locking bolt, with T handle

Complementary products



ACAss
Stainless steel splined shaft, Stainless steel



ACA
Steel splined shaft, Steel