

- Suitable for transmitting high torque

- Materials:

Steel C40/XC42



- Extruded product

### Accessories

- Splined bush: cylindrical or flanged

### Options

- Alternative lengths up to 3000mm

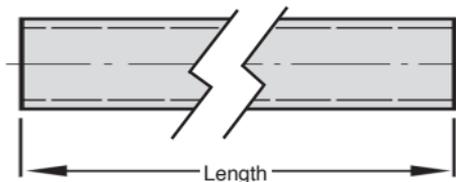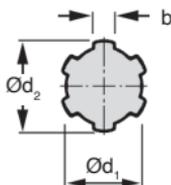

### DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	30+	40+
disc	List	-15%	-20%	-30%	On request
L.	1000 mm		2000 mm		3000 mm
Price	Uni.		x 2,23		x 3,35

Part number	Number of splines	$\text{Ød}_1$	$\text{Ød}_2$	b	Standard length (mm)	Weight (kg)	Stock*	Price each 1 to 9
ACA6-14-1000	6	11 $^{+0,08}_{-0,08}$	14 $^{-0,07}_{-0,2}$	3,0 $^{+0,08}_{-0,08}$	1000	0,949	✓	40,51 €
ACA6-16-1000	6	13 $^{+0,08}_{-0,08}$	16 $^{-0,07}_{-0,2}$	3,5 $^{+0,08}_{-0,08}$	1000	1,287	✓	38,80 €
ACA6-20-1000	6	16 $^{+0,08}_{-0,08}$	20 $^{-0,07}_{-0,25}$	4,0 $^{+0,08}_{-0,08}$	1000	1,911	✓	52,07 €
ACA6-22-1000	6	18 $^{+0,08}_{-0,08}$	22 $^{+0,08}_{-0,10}$	5,0 $^{+0,08}_{-0,08}$	1000	2,453	✓	59,03 €
ACA6-25-1000	6	21 $^{+0,08}_{-0,08}$	25 $^{-0,07}_{-0,27}$	5,0 $^{+0,08}_{-0,08}$	1000	3,139	✓	67,49 €
ACA6-28-1000	6	23 $^{+0,08}_{-0,08}$	28 $^{-0,07}_{-0,25}$	6,0 $^{+0,08}_{-0,08}$	1000	3,964	✓	90,75 €
ACA6-32-1000	6	26 $^{+0,08}_{-0,08}$	32 $^{-0,07}_{-0,27}$	6,0 $^{+0,08}_{-0,08}$	1000	5,008	✓	111,14 €
ACA6-34-1000	6	28 $^{+0,08}_{-0,08}$	34 $^{-0,07}_{-0,27}$	7,0 $^{+0,08}_{-0,08}$	1000	5,816	✓	131,16 €
ACA8-38-1000	8	32 $^{+0,08}_{-0,08}$	38 $^{-0,07}_{-0,27}$	6,0 $^{+0,08}_{-0,08}$	1000	7,433	✓	162,64 €
ACA8-42-1000	8	36 $^{+0,08}_{-0,08}$	42 $^{-0,07}_{-0,27}$	7,0 $^{+0,08}_{-0,08}$	1000	9,302	✓	211,13 €
ACA8-48-1000	8	42 $^{+0,08}_{-0,08}$	48 $^{-0,07}_{-0,27}$	8,0 $^{+0,08}_{-0,08}$	1000	12,371	✓	267,83 €
ACA8-54-1000	8	46 $^{+0,08}_{-0,08}$	54 $^{-0,07}_{-0,27}$	9,0 $^{+0,08}_{-0,08}$	1000	15,300	-	389,75 €

\*Depending on availability - Dimensions in mm



- Suitable for transmitting high torque

- Material:

Steel C45

### Accessories

- Steel or stainless steel splined shaft

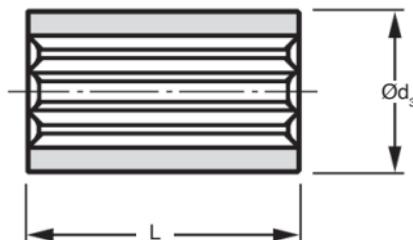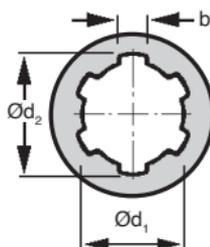

### DISCOUNTS

Qty	1+	10+	20+	30+	40+
Disc.	List	-15%	-20%	-30%	On request

Part number	Number of splines	L			splined length	$\varnothing d_3$	Stock*	Price each 1 to 9	
		$\varnothing d_1$	$\varnothing d_2$	b					
BCA6-14	6	11,00	14,00	3,00	40	30	25	✓	16,55 €
BCA6-16	6	13,00	16,00	3,50	40	40	28	✓	15,59 €
BCA6-20	6	16,00	20,00	4,00	50	50	30	✓	15,59 €
BCA6-22	6	18,00	22,00	5,00	50	50	32	✓	15,59 €
BCA6-25/40	6	21,00	25,00	5,00	40	40	38	✓	18,37 €
BCA6-25	6	21,00	25,00	5,00	60	60	38	✓	18,37 €
BCA6-28	6	23,00	28,00	6,00	60	60	38	✓	19,09 €
BCA6-32	6	26,00	32,00	6,00	60	60	42	✓	19,09 €
BCA6-34	6	28,00	34,00	7,00	60	60	45	✓	21,41 €
BCA8-38	8	32,00	38,00	6,00	60	60	55	✓	31,30 €
BCA8-42	8	36,00	42,00	7,00	70	70	60	✓	36,62 €
BCA8-48	8	42,00	48,00	8,00	70	70	65	✓	45,53 €
BCA8-54	8	46,00	54,00	9,00	80	80	70	✓	60,70 €

\* Depending on availability - Dimensions in mm

# Stainless steel 304 splined shaft

## ACA<sub>SS</sub>

## Parallel-faced

- Suitable for transmitting high torque values

- Material:



Stainless steel 304 (1.4301)

### Accessoires

- Stainless steel splined bush **BCA<sub>SS</sub>**

### Option

- Alternative lengths up to 3000mm

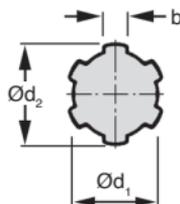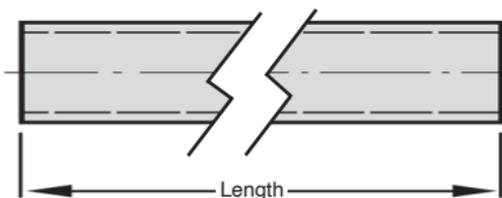

**For hostile environments**

### DISCOUNTS

<b>Qty</b>	1+	2+	20+
<b>Disc.</b>	List	-10%	On request

Part number	Number of splines	$\varnothing d_1^{+0,08}$	$\varnothing d_2^{-0,07,0,27}$	$b^{+0,08}$	Standard length (mm)	Weight (kg/m)	Stock*	Price each for 1000mm
ACA6-14-1000/SS	6	11,00	14,00	3,00	1000	0,949	✓	79,34 €
ACA6-16-1000/SS	6	13,00	16,00	3,50	1000	1,287	✓	92,94 €
ACA6-20-1000/SS	6	16,00	20,00	4,00	1000	1,911	✓	164,51 €
ACA6-25-1000/SS	6	21,00	25,00	5,00	1000	3,139	✓	269,40 €
ACA6-32-1000/SS	6	26,00	32,00	6,00	1000	5,008	✓	412,71 €
ACA8-38-1000/SS	8	32,00	38,00	6,00	1000	7,433	-	591,88 €



\*Depending on availability - Dimensions in mm

- Suitable for transmitting high torque values
- Materials:  
Stainless steel 304

**Accessories**

- Stainless steel splined shaft ACAss

For hostile environments

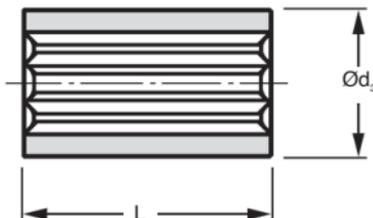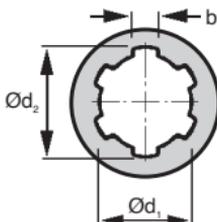**DISCOUNTS**

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	$\text{Ød}_{H7}$	$\text{Ød}_2$	$b^{D9}$	L	$\text{Ød}_3^{H11}$	Weight (kg)	Stock*	Price each
BCA6-14/SS	6	11,00	14,00	3,00	25	18,75	0,028	✓	36,94 €
BCA6-16/SS	6	13,00	16,00	3,50	30	21,75	0,047	✓	43,38 €
BCA6-20/SS	6	16,00	20,00	4,00	30	28,50	0,090	✓	48,24 €
BCA6-25/SS	6	21,00	25,00	5,00	40	36,00	0,190	✓	68,22 €
BCA6-32/SS	6	26,00	32,00	6,00	40	42,50	0,242	✓	87,81 €
BCA8-38/SS	8	32,00	38,00	6,00	40	49,70	0,304	✓	102,54 €

\*Depending on availability - Dimensions in mm