
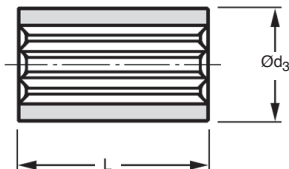


- Suitable for transmitting high torque values
- Materials:
Stainless steel 304

Accessories

- Stainless steel splined shaft ACAss

For hostile environments

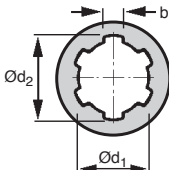

NEW!
Replace the part
number BUC00

DISCOUNTS

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	Ød_{1H7}	Ød_2	b^{D9}	L	Ød_3^{H11}	Weight (kg)	Price each
BCA6-14/SS	6	11,00	14,00	3,00	25	18,75	0,028	27,87 €
BCA6-16/SS	6	13,00	16,00	3,50	30	21,75	0,047	32,74 €
BCA6-20/SS	6	16,00	20,00	4,00	30	28,50	0,090	36,40 €
BCA6-25/SS	6	21,00	25,00	5,00	40	36,00	0,190	51,48 €
BCA6-32/SS	6	26,00	32,00	6,00	40	42,50	0,242	66,26 €
BCA8-38/SS	8	32,00	38,00	6,00	40	49,70	0,304	77,37 €


Dimensions in mm

Our other products



MSP19

 Masterplate® glueable insert
Ø19/Ø20, Cylindrical with nut



T2

T type timing belt,
T.2.5 Steel cored polyurethane



NTM

Nylon tipped set screw, Nylon-point



SSDB

Stainless steel bevel gear, 2:1



PTRSS

Idler chain sprocket,
For hostile environments



CLQ

12.7mm wide steel feeler strip on rolls,
Feeler strip on rolls



ZG0

Plastic spur gear,
Machined plastic (delrin)



FF20

Offset spur gear reducer, from 5.80 to 23 Nm



SHSS

Shoulder screw stainless steel 416,



PTAF100-PAMF100

Articulated fixable foot with pressed



WJUM10

Drylin® W bearing block, Slide



EIM

Stainless steel U bolt, Stainless steel

Complementary products



ACAss

Stainless steel splined shaft, Stainless steel



ACA

Steel splined shaft, Steel



BCA

Steel splined collar, Steel