
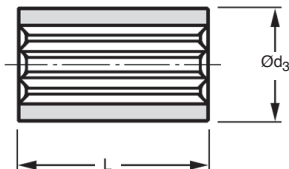


- Suitable for transmitting high torque values
- Materials:
Stainless steel 304

Accessories

- Stainless steel splined shaft ACAss

For hostile environments

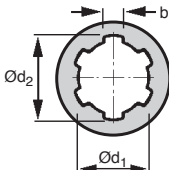

NEW!
Replace the part
number BUC00

DISCOUNTS

Qty	1+	2+	20+
Disc.	List	-10%	On request

Part number	Number of splines	$\varnothing d_{1H7}$	$\varnothing d_2$	b^{D9}	L	$\varnothing d_3^{H11}$	Weight (kg)	Price each
BCA6-14/SS	6	11,00	14,00	3,00	25	18,75	0,028	27,87 €
BCA6-16/SS	6	13,00	16,00	3,50	30	21,75	0,047	32,74 €
BCA6-20/SS	6	16,00	20,00	4,00	30	28,50	0,090	36,40 €
BCA6-25/SS	6	21,00	25,00	5,00	40	36,00	0,190	51,48 €
BCA6-32/SS	6	26,00	32,00	6,00	40	42,50	0,242	66,26 €
BCA8-38/SS	8	32,00	38,00	6,00	40	49,70	0,304	77,37 €

Dimensions in mm

Our other products



ZG2
Plastic spur gear,
Machined plastic
(delrin)



GAL 42
Guide roller for plate
chain return, Without
ball bearing



MFBSO
Stainless steel flexible
bellows coupling,
Stainless steel - with cl...



PITA
Locking bolt, with T
handle



KB_WW
Closed linear
precision bearing,
Economy range



MSP23
Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with
threaded s...




SH1
Parallel axis helical
gear, Machined plastic
(delrin)



VRM
Female swivelling
lifting rings, Female
swivelling



 
BOX-CSss
Hose clamp, Box set
of stainless steel hose



HD
Double needle roller
universal joint, Heavy



 RPP
Connecting plate for
RPP type timing belts,
Nylon



CRM
Moulded nylon rack,
Nylon

Complementary products



ACAss
Stainless steel splined
shaft, Stainless steel



ACA
Steel splined shaft,
Steel