


# Modular cylindrical brush

## Introduction

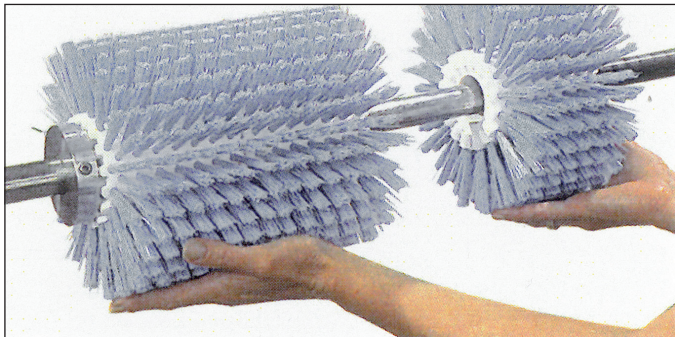

### Info.

These perforated roller brushes are suitable for many applications such as washing, conveying, dusting or transport.


Each brush is 100mm long, longer lengths can be achieved by mounting several brushes on the same shaft. Teeth on the end of each brush ensure a quick and firm fitting. A driving collar is required at each end to hold the brushes in place and to ensure correct rotation.

### Bristles


Different applications will require different combinations of bristle material and length. PBT polyester bristles are available in 2 different lengths for washing and transport applications, horsehair or Tampico is more suitable for dusting.

### Density

Each brush is available with different bristle densities; low, medium or high (see photos).

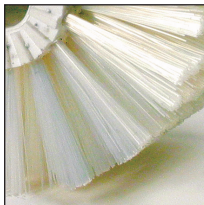

Low bristle density

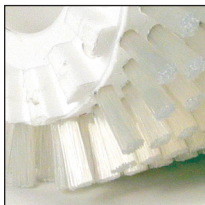

Medium bristle density



High bristle density



# Modular cylindrical brush Tampico bristles

## For dusting applications

## BCM<sub>TP</sub>

- Suitable for dusting removal
- Brushes can be attached together to form longer brushes
- Materials:
  - Bristles: tampico
  - Body: polypropylene
  - Stitching wire: stainless steel 316L
- Bristle height 50 mm

*new training profile*




### Advantages

- Antistatic
- Tampico can be used in wet environments
- Very high abrasion resistance
- Very good sweeping power

### Accessory

- Driving collar BCM-T (tome 5 p.191)

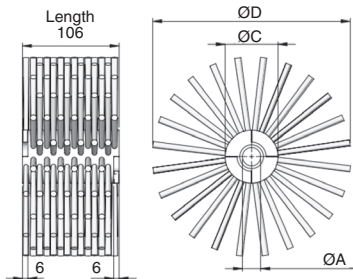

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	External ØD	Body ØC	Bore ØA	Bristle density	No. of teeth	No. of rows	Stock*	Price each
BCM30-130M/TP	130	30	12	medium	1	8	✓	48,38 €
BCM58-155M/TP	155	58	20	medium	2	24	-	39,88 €
BCM78-180M/TP	180	78	30	medium	2	32	-	45,38 €
BCM108-210M/TP	210	108	40	medium	2	40	-	54,63 €

\*Depending on availability - Dimensions in mm

# Modular cylindrical brush **PBT polyester bristles**

## BCMPBT

## For transport applications



- Suitable for moving products
- Brushes can be attached together to form longer brushes
- Materials:
  - Bristles: blue PBT polyester
  - Body: polypropylene
  - Stitching wire: stainless steel 316L
- Bristle diameter 0.35 mm
- Bristle height 15 mm

### Advantages

- Does not collect moisture
- Bristles resist up to 120°C
- Recommended for use in food industries

### Accessory

- Driving collar BCM-T (tome 5 p.191)

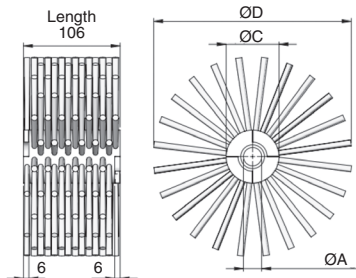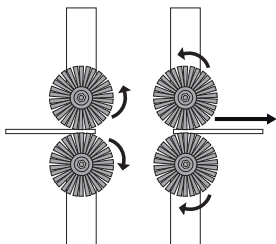

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	External ØD	Body ØC	Bore ØA	Bristle density	No. of teeth	No. of rows	Stock*	Price each
BCM30-60H/PBT	60	30	12	high	1	16	✓	55,25 €
BCM58-85H/PBT	85	58	20	high	2	32	-	43,25 €
BCM78-110H/PBT	110	78	30	high	2	48	-	52,75 €
BCM108-140H/PBT	140	108	40	high	2	56	-	61,75 €

\*Depending on availability - Dimensions in mm



# Modular cylindrical brush PBT polyester bristles

For washing applications

BCM/PBT

- Suitable for washing products
- Brushes can be attached together to form longer brushes
- Materials:
  - Bristles: blue PBT polyester
  - Body: polypropylene
  - Stitching wire: stainless steel 316L
- Bristle diameter 0.50 mm
- Bristle height 50 mm

Food industry

new training profile





## Advantages

- Does not collect moisture
- Bristles resist up to 120°C
- Recommended for use in food industries

## Accessory

- Driving collar BCM-T (tome 5 p.191)

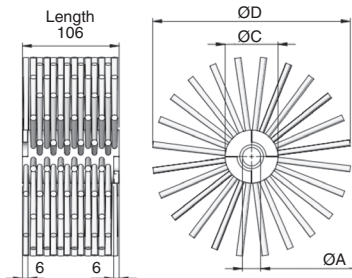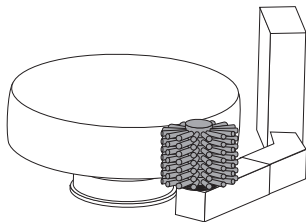

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	External Body		Bore ØA	Bristle density	No. of teeth	No. of rows	Stock*	Price each
	ØD	ØC						
BCM30-130M/PBT	130	30	12	medium	1	16	✓	48,38 €
BCM58-155M/PBT	155	58	20	medium	2	24	-	39,88 €
BCM58-155B/PBT	155	58	20	low	2	16	-	34,25 €
BCM78-180M/PBT	180	78	30	medium	2	32	-	45,38 €
BCM78-180B/PBT	180	78	30	low	2	24	-	39,13 €
BCM108-210M/PBT	210	108	40	medium	2	40	-	54,63 €
BCM108-210H/PBT	210	108	40	low	2	32	-	47,75 €

\*Depending on availability - Dimensions in mm

# Modular cylindrical brush Horsehair bristles



## BCMcc

## For dusting applications

- Suitable for dusting removal
- Brushes can be attached together to form longer brushes
- Materials:
  - Bristles: horsehair
  - Body: polypropylene
  - Stitching wire: stainless steel 316L
- Antistatic
- Bristle height 50 mm



### Advantages

- Horsehair is less responsive, less rigid, and less abrasive than Tampico
- Recommended for use in for dry environments

### Accessory

- Driving collar BCM-T (tome 5 p.191)

Use in dry environments  
new training profile

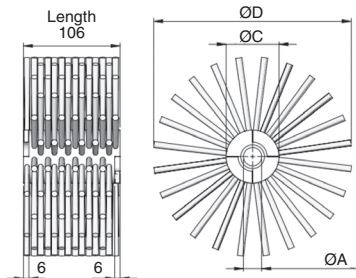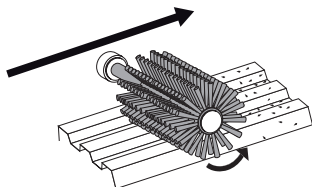

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	External ØD	Body ØC	Bore ØA	Bristle density	No. of teeth	No. of rows	Stock*	Price each
BCM30-130M/CC	130	30	12	medium	1	8	-	59,88 €
BCM58-155M/CC	155	58	20	medium	2	24	-	62,50 €
BCM78-180M/CC	180	78	30	medium	2	32	-	75,63 €
BCM108-210M/CC	210	108	40	medium	2	40	-	92,38 €

\*Depending on availability - Dimensions in mm



# Driving collar

## Driving collar for BCM cylindrical brush

BCMT

### - Driver for BCM cylindrical brush

- Materials:  
Glass fiber reinforced polypropylene (PP)

### Usage


- Required for holding brushes in place and to ensure rotation

### How to choose

- Brush and collar should have identical body and bore diameters irrespective of bristle density.
- Two collars required per application.



*new training profile*

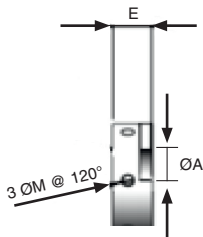

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Body ØC	Bore ØA	ØM	E	Bristle density	No. of teeth	Stock*	Price each
							✓	
BCM30-T	30	12	M6	18,5	high medium low	1	✓	31,45 €
BCM58-T	58	20	M6	18,5	high medium low	2	-	24,13 €
BCM78-T	78	30	M6	18,5	high medium low	2	-	24,50 €
BCM108-T	108	40	M8	25	high medium low	2	-	27,50 €

\*Depending on availability - Dimensions in mm

## Our other products



CTZYSS

Stainless steel diablo shaped elasto mount, Stainless steel



UTKswc

Utilitrak® 3 wheels carriage, Series V precision steel wheel




ACLBTS

Spherical ended stop for aluminium profile, Spherical ended stop



DOMI120

 Connecting kits, XZ linking kit



MF

Shock Absorber -universal flange, Universal fixing



GLT3-46

Telescopic drawer,



HTD8M\_50

HTD Heavy duty timing pulley, HTD8 Cast



NDS14C

Angular connector, Universal angular connector



ZG1

Plastic spur gear, Machined plastic (delrin)



RBGtc

Swivel castor with central hole, Steel - grey rubber



CFF

Female rod ends DIN ISO12240-4, Steel / bronze



KB\_WW

Closed linear precision bearing, Economy range

## Complementary products



BCM\_T

Driving collar, Driving collar



BCM\_MPBT

Modular cylindrical brush, PBT polyester bristles