

# Modular cylindrical brush **PBT polyester bristles**

## BCMPBT For transport applications

- Suitable for moving products
- Brushes can be attached together to form longer brushes
- Materials:
  - Body: polypropylene
  - Bristles: PBT polyester
  - Stitching wire: stainless steel 316L
- Bristle diameter 0.35 mm
- Bristle height 15 mm




### Accessory

- Driving collar BCM-T

### Advantages

- Does not collect moisture
- Bristles resist up to 132°C
- Recommended for use in food industries

**Food industry**

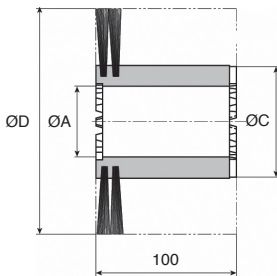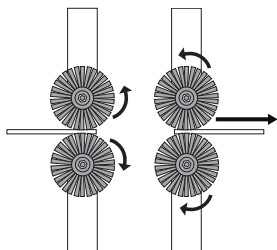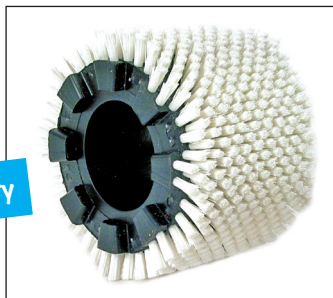

### DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%	On request	

Part number	External ØD	Body ØC	ØA	Bristle density	No. of teeth	No. of rows	Stock*	Price each
BCM30-60H/PBT	60	30	12	high	8	16	✓	35,46 €
BCM55-85H/PBT	85	55	25	high	16	32	✓	36,30 €
BCM80-110H/PBT	110	80	30	high	16	32	-	39,81 €
BCM110-140H/PBT	140	110	60	high	8	48	-	72,48 €

\*Depending on availability - Dimensions in mm

## Our other products



NT63  
Spur gear coaxial gearbox, from 8 to 20 Nm - In-line



M2  
Worm and wheel set, Unhardened steel



GDR880  
Straight track for plate chain, Ranges 880 and 881



BLH70  
Right angled gearbox, from 26 to 128 Nm



PSG08S  
Spur gear - precision range, Stainless steel 316



G2  
Steel spur gear, Steel 20NCD2



G0  
Steel spur gear, Steel 20NCD2



PRF\_GAL  
Roller for aluminium profile, Fixing kit for roller eccentric



RBN  
Wheel, Rubber tyre - Polypropylene rim



NPTF20  
Fixed tube carrier, Fixed Ø10 to Ø14



ESST  
Support base (tripod), Tripod support base




CHT63  
Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW

## Complementary products



 BCM\_T  
Driving collar, Driving collar



BCM\_MPBT  
Modular cylindrical brush PBT polyester bristles, PBT polyester bris...