

Mushroom knob with male thread and high head

BCFH_{HUSS}

Hygienic Usit®


- **Mushroom knob with a male thread and high head for use with Hygienic Usit® sealing washers®**
- The high head makes this mushroom knob ideal for manual lateral movements.
- Fully polished surface with a roughness much lower than Ra0.8µm.
- Material:
 - Stainless steel 1.4404 (316L)
 - Mirror polished finish

Advantages

- Regardless of the mounting position of the mushroom knob, dirt and residue from product or cleaning material will not adhere. This guarantees easy cleaning.
- USIT® Hygienic sealing washers are used to seal the screwed connection.
- The stem of the mushroom knob is specially designed to ensure an almost cavity free seal thus meeting hygiene requirements.

Accessory

- RDE sealing washers
(tome 1 p.607 to p.609)

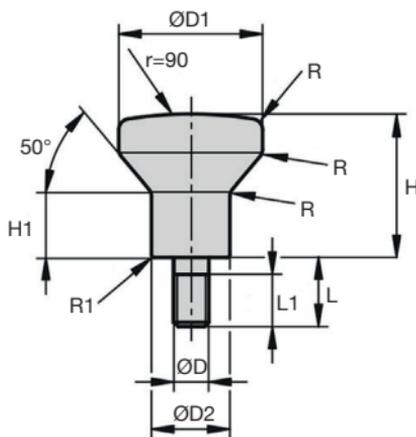

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	Prix	-5%	-10%	On request

Part number	ØD	ØD1	ØD2	H	H1	L	L1	R	R1	Price each
										1 to 4
BCFH-4/HUSS	M4	20	10,8	19	8	8	7	3	0,45	15,12 €
BCFH-5/HUSS	M5	21	11,8	21	10	10	9	3	0,50	16,35 €
BCFH-6/HUSS	M6	25	14,2	25	12	12	11	3	0,55	18,20 €
BCFH-8/HUSS	M8	33	18,0	33	15	16	15	4	0,60	30,63 €
BCFH-10/HUSS	M10	40	22,3	40	19	20	19	4	0,75	32,71 €

All dimensions in mm



Mushroom knob with female thread and high head

Hygienic Usit®

BCTH_{HUSS}

- Mushroom knob with a female thread and high head for use with Hygienic Usit® sealing washers
- The high head makes this mushroom knob ideal for manual lateral movements.
- Fully polished surface with a roughness much lower than Ra0.8µm.
- Material:
Stainless steel 1.4404 (316L)
Mirror polished finish




Advantages

- Regardless of the mounting position of the mushroom knob, dirt and residue from product or cleaning material will not adhere. This guarantees easy cleaning.
- USIT® Hygienic sealing washers are used to seal the screwed connection.
- The base of the mushroom knob is designed to ensure an almost cavity free seal thus meeting hygiene requirements.

Accessory

- RDE sealing washers (tome 1 p.607 to p.609)

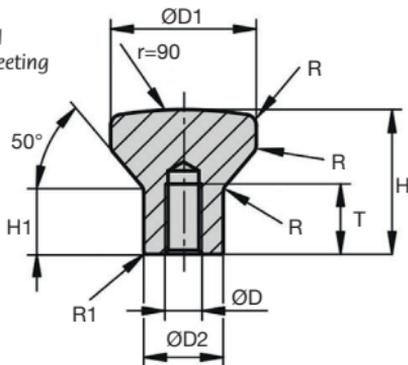

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	Net	-5%	-10%	On request

Part number	ØD	ØD1	ØD2	H	H1	T	R	R1	Price each
									1 to 4
BCTH-4/HUSS	M4	20	10,8	19	8	10	3	0,45	15,20 €
BCTH-5/HUSS	M5	21	11,8	21	10	12	3	0,50	15,81 €
BCTH-6/HUSS	M6	25	14,2	25	12	12	3	0,55	17,58 €
BCTH-8/HUSS	M8	33	18,0	33	15	16	4	0,60	28,42 €
BCTH-10/HUSS	M10	40	22,3	40	19	20	4	0,75	30,31 €

All dimensions in mm