

Adjustable support arm



BDP1R

Single grip



- **Universal rigid support arm , adjustable**

- Material :

Aluminium with steel screws

Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

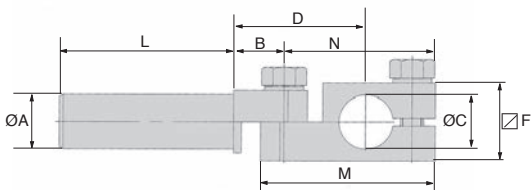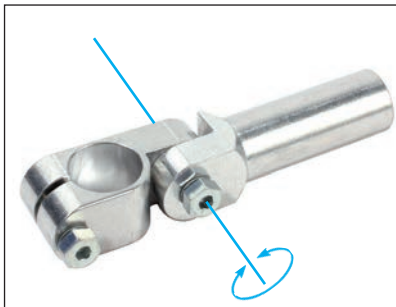

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	Weight	Price each
									(g)	1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	55,51 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	61,04 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	61,59 €

Dimensions in mm

Our other products



CFF

Female rod ends DIN ISO12240-4, Steel / bronze



CHAFR-MINI

Miniature friction hinge, Friction



E20

Right angle helical reducers, from 0.60 to 3.84 Nm



ACLALF

Adjustable foot for aluminium profile, Ideal for workstations



UFX

Uneflex® elastic coupling, range



RTE

Rotex®, jaw coupling, steel



BEK

Bearing housing for miniature ballscrew, Bearing housing



CAP821

Slat top chain acetal, Large range 821



SVT20

Screwjack with travelling screw, with



H2

Crossed helical gear crossed axis at 90°



DOG316

Motor-gearbox 12V and 24V DC, from 1.5



BLH70

Right angled gearbox, from 26 to 128 Nm

Complementary products



BDP2R

Adjustable support arm, Increased grip



BDPR

Holding arm, Rigid