

Adjustable support arm



BDP1R

Single grip



- **Universal rigid support arm , adjustable**

- **Material :**

Aluminium with steel screws

Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

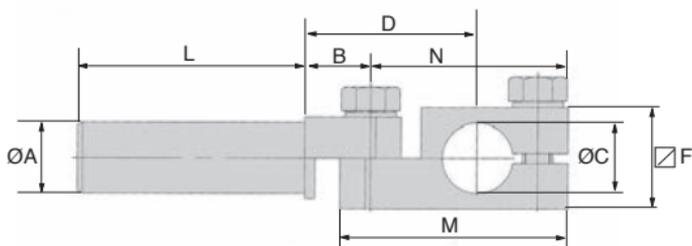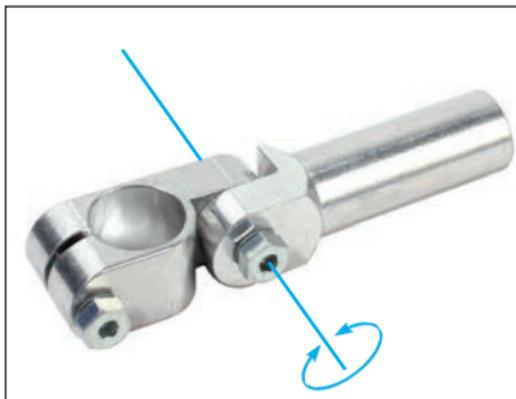

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	Weight	Price each
									(g)	1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	55,51 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	61,04 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	61,59 €

Dimensions in mm

Our other products



NT63

Spur gear coaxial gearbox, from 8 to 20 Nm - Inline



PPS

Lifting ring, Universal threaded



LR

Precision locknut, Precision locknut



GCL

Linear ball slide Eco Range, economy range



DOMI30

Connecting kits, XZ linking kit



PCS37

Chain sprocket - steel, 9.525mm (DIN06B-1)



BLHB30

Right angled gearbox, bored shafts, up to 4.47 Nm



PDM_PDV

Detectable plastic palm grip, by metal detectors




CHTRP

Single and dual output gearboxes, Up to 20 Nm



PCF2

Conical flexible mount, Oval base

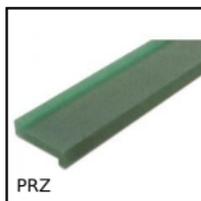

PRZ

Wear strip for slat top chain, Z profile to be 10mm



SLB

Indexing plunger, steel class 5.8

Complementary products



BDP2R

Adjustable support arm, Increased grip



BDPR

Holding arm, Rigid