

Adjustable support arm



BDP1R

Single grip



- Universal rigid support arm , adjustable

- Material :

Aluminium with steel screws

Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

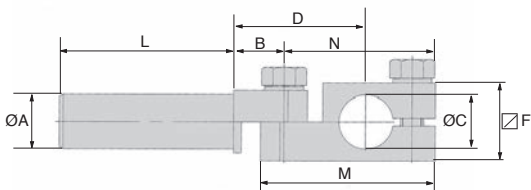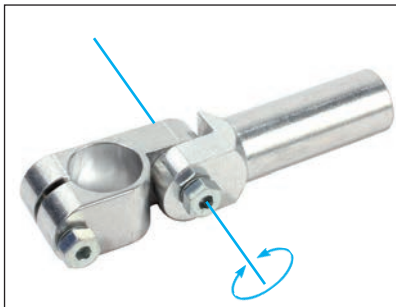

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	Weight (g)	Price each 1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	55,51 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	61,04 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	61,59 €

Dimensions in mm

Our other products



PAS

Pull handle,
Reinforced PA
thermoplastic



AHEX

Hexagonal shaft,
Hexagonal nut



TS01_TW01

Drylin® T linear slide,
up to 7000 N



NT61

Spur gear coaxial
gearbox, from 5 to 14
Nm - In-line



GBSz

Cylindrical ballscrew
nut, Cylindrical
leadscrew nut



BS3

Panamech, Multi-
Beam stainless steel,
Stainless steel - with
set screw



PLA

Flat magnet, Flat
magnet with thread



HSSss

Stainless steel
shoulder screw
ISO7379, Stainless
steel ISO 7379



CHA60

Rectangular hinge,
drilled or countersunk,



E15

Right angle helical
reducers, from 0.40 to



SA_SAKH

Housing for linear
bearing, Closed - light



ERC

Quick fitting cable
terminal, Eye version

Complementary products



BDP2R

Adjustable support
arm, Increased grip



BDPR

Holding arm, Rigid