

# Adjustable support arm



## BDP1R

## Single grip



- **Universal rigid support arm , adjustable**

- Material :

Aluminium with steel screws

### Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

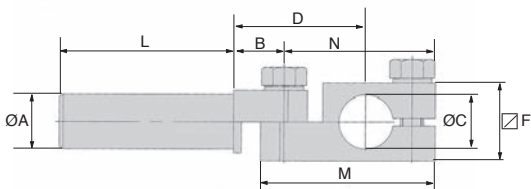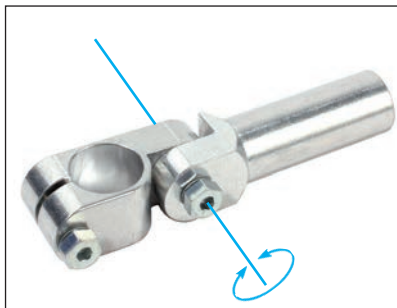

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	Weight	Price each
									(g)	1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	55,51 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	61,04 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	61,59 €

Dimensions in mm

## Our other products



SHSS

Shoulder screw stainless steel 416, Pre-treated 416 stainless steel



RTE

Rotex®, jaw coupling, Aluminium



KB\_UU

Closed linear precision bearing, Precision - steel



CLM

Male clevis end, Stainless steel short



SBF

Sealed flange bearing unit for Food Industry, cover



CLG3

Moulded plastic spur gear, Moulded plastic (nylon)



MSP38

Masterplate® glueable insert Ø38, Cylindrical Ø38 with tapped ins...



NSR

Adjustable clamp, Adjustable



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - steel



GE32

Sprung toggle latch with connecting link, Standard



SSB

Stainless steel bevel gear, 1:1



HLC19

Right angle spiro bevel gearbox, Up to 43Nm

## Complementary products



BDP2R

Adjustable support arm, Increased grip



BDPR

Holding arm, Rigid