

Adjustable support arm



BDP1R

Single grip



- Universal rigid support arm , adjustable

- Material :

Aluminium with steel screws

Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

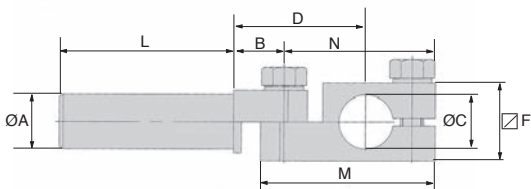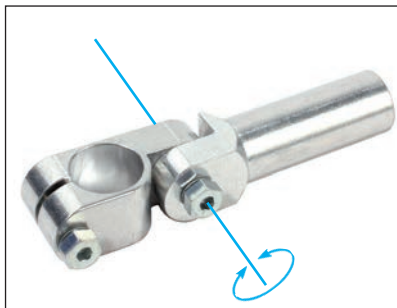

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	Weight	Price each
									(g)	1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	55,51 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	61,04 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	61,59 €

Dimensions in mm

Our other products



CHT56

Asynchronous AC motor 0.09kW, 0.09kW



PW_PWG25

Worm - precision range, Stainless steel



RVM25

Manually operated gearbox, Bevel



PPD

Indexing plunger for sheets, For sheet metal



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



BOXKK

Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



SLHHlok

Horizontal toggle clamp, Horizontal toggle clamp / horizontal foot



ZDB

Machined plastic bevel gear , 2:1



DSF

Slip friction clutch, 4 to 2600 Nm



VTH

Hexagonal headed bolts, Steel class 8.8



DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



CLG3

Moulded plastic spur gear, Moulded plastic (nylon)

Complementary products



BDP2R

Adjustable support arm, Increased grip



BDPR

Holding arm, Rigid