



Adjustable support arm

Increased grip

BDP2R



- **Universal adjustable support arm, strengthened**

- Material :

Aluminium with steel screws

Advantages

- Safe in operation through use of optimised jaw support
- Lighter

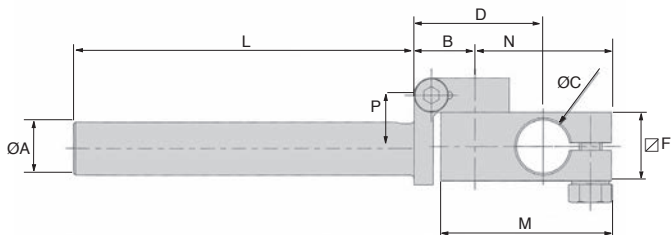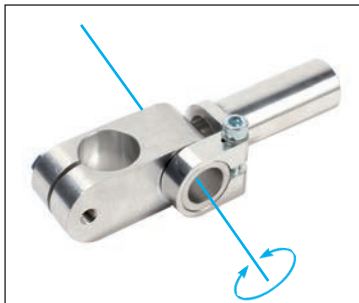

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	97,18 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	103,15 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	109,09 €

Dimensions in mm

Our other products



CM_CO

Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...




CLB_T

Die cast zinc clamping lever - male, Zamak



PRF1932

Standard aluminium profile, 19 x 32 mm

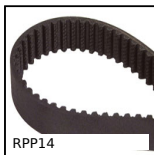

RPP14

RPP heavy duty timing belt, RPP14



UCP_PBT

Stainless/Polymer pillow block bearing, Polymer and stainless steel



BUH77

Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm



PDM_PDV

Detectable plastic palm grip, blue thermoplastic



WSSss

Symmetrical S shaped hook stainless steel, Stainless steel



BPM-Z

Plastic slotted spring plunger with ball tip, Plastic body +



GAL21

Conveyor wheel, Plastic



PTRSS

Idler chain sprocket, For hostile environments



PCLA_M

Technopolymer clamping lever - female, Plastic

Complementary products



BDPR

Holding arm, Rigid



BDP1R

Adjustable support arm, Single clamp