



Adjustable support arm

Increased grip

BDP2R


- **Universal adjustable support arm, strengthened**

- Material :

Aluminium with steel screws

Advantages

- Safe in operation through use of optimised jaw support
- Lighter

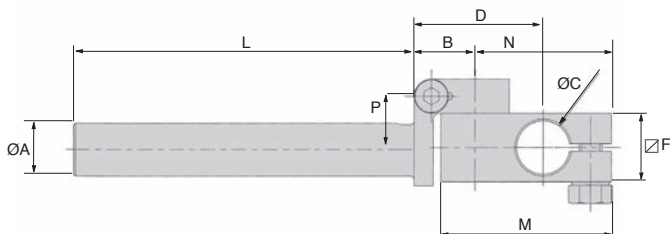

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	√F	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	97,18 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	103,15 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	109,09 €

Dimensions in mm

Our other products



BLHT50

Right angled gearbox,
from 11.50 to 30 Nm



WJUM16

Drylin® W bearing
block, Slide



MLY

Bow shackle with eye
bolt, Steel




HAR9

Captive C washer, DIN
6371



VMS

 Stainless steel knurled
thumb screw, Knurled



LWL

High rigidity linear
slide, Chariot - from
9320 N to 71300 N




PSG15

Spur gear - precision
range, Pre-hardened
Steel 35NCD6



LVT

 Miniature motorised
actuator 4A, 4 amperes



IN1

Internal gear,
Machined plastic



S_ZZ

Deep groove ball
bearing, Stainless



TCXR

Automatic chain
tensioner, With steel



DOMI120

Connecting kits, XZ
linking kit

Complementary products



BDPR

Holding arm, Rigid



BDP1R

Adjustable support
arm, Single clamp