



Adjustable support arm

Increased grip

BDP2R


- **Universal adjustable support arm, strengthened**

- Material :

Aluminium with steel screws

Advantages

- Safe in operation through use of optimised jaw support
- Lighter

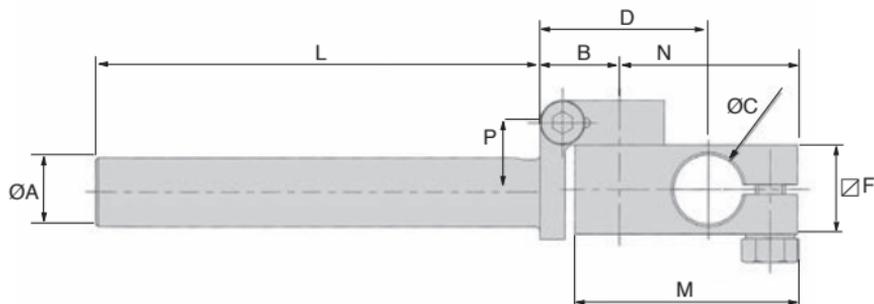

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	97,18 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	103,15 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	109,09 €

Dimensions in mm

Our other products



TCC
Rigging screw
(hook/hook), Steel



PARF110
Pressed steel base
rigid foot, Swivelling
Ø110



WSRM
Cylindrical polymer
nut, Polymer
(Iglidur®) - 1 thread



SBF
Sealed flange bearing
unit for Food Industry,
cover



VPPTss
Stainless steel
handwheel with
handle, Stainless steel
304



CHTRB
Single and dual
output gearboxes, Up
to 87,3 Nm



ZBconique
Machined plastic
bevel gear, 1:1




CDR
Retaining cable for
ball pin, Retaining
cable



BOXKK
Boxed set of
DIN6885A keys,
Boxed set - Steel or



FGWA
End support, With
base

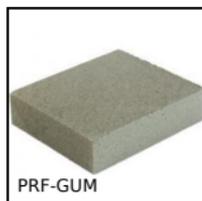

PRF-GUM
Aluminium profile
anodising polisher,
Polishing block



BPF
Sheet steel flanged
bearing for light
loads, Sheet steel

Complementary products



BDPR
Holding arm, Rigid



BDP1R
Adjustable support
arm, Single clamp