



# Adjustable support arm

Increased grip

BDP2R



- **Universal adjustable support arm, strengthened**

- Material :

Aluminium with steel screws

## Advantages

- Safe in operation through use of optimised jaw support
- Lighter

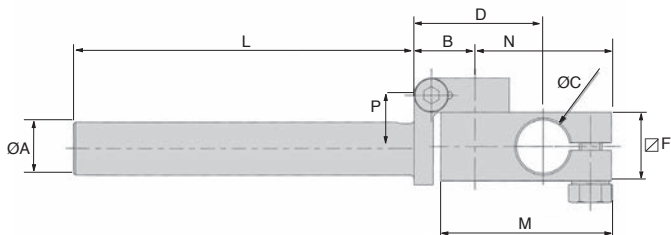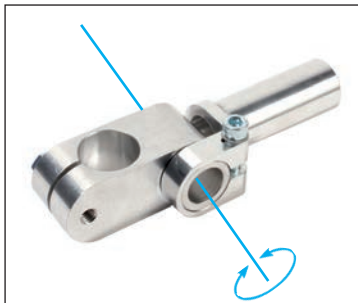

## DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	97,18 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	103,15 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	109,09 €

Dimensions in mm

## Our other products



LF

Precision locknut,  
Precision locknut



PGMT

Pull handle, Steel



GAL\_20

Conveyor roller for  
Ø20mm spindle, Self-  
lubricating polyamide



DOMI\_MD

Domino rotary table,  
40/1



CQA20

Adjustment slide-  
system miniature, 20



MAX22

Motor-gearbox 12V  
and 24V DC, from  
0,07 to 0,2Nm



PRF-SRA

Lock for aluminium  
profile, Lock



CFES

Eccentric cam  
follower, Eccentric




BOXKK

Boxed set of  
DIN6885A keys,  
Boxed set - Steel or



PTA50

 Articulated levelling  
foot, pressed base  
Ø50, 4000N



JFM

Flanged polymer  
bush, Universal  
polymer



ACLBS

Spherical ended stop  
for aluminium profile,  
Spherical ended stop

## Complementary products



BDPR

Holding arm, Rigid



BDP1R

Adjustable support  
arm, Single clamp