



Adjustable support arm

Increased grip

BDP2R



- **Universal adjustable support arm, strengthened**

- Material :

Aluminium with steel screws

Advantages

- Safe in operation through use of optimised jaw support
- Lighter

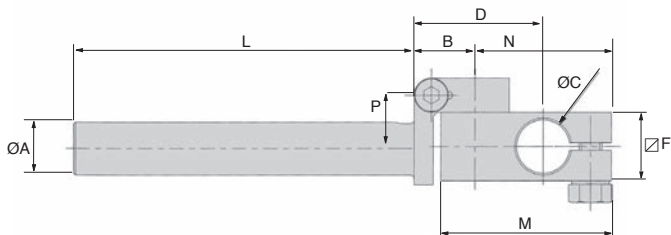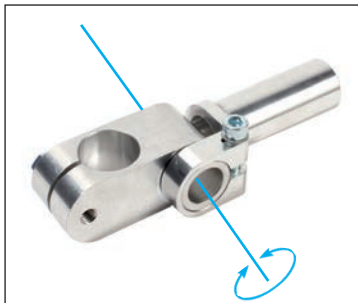

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∇F	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	97,18 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	103,15 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	109,09 €

Dimensions in mm

Our other products



T5P_T10P
Connecting plate for T type timing belts, T10



CHALss
Piano hinge, Stainless steel



LVT
Miniature motorised actuator 2A, 2 amperes



PCF4
Conical flexible mount, Square base plate



PP50
Worm and wheel gear reducer, from 6.50 to 12.80 Nm



DB
Steel bevel gear, 2:1




AT5-25ECO
AT type timing pulley, Economy range - AT5 aluminium



ACLDBB
Closing mechanism for aluminium profile, Dual ball catch



 BPM_LOK
Long-Lok slotted spring plunger with



KS
Keystock, Steel - Keystock



CHAFR-MINI
Miniature friction hinge, Miniature



SSB
Stainless steel bevel gear, 1:1

Complementary products



BDPR
Holding arm, Rigid



BDP1R
Adjustable support arm, Single clamp