


- **Universal support arm**
- **Material :**  
Aluminium with steel screws

### Advantages

- **Reliable operation**
- **Flexible mounting**

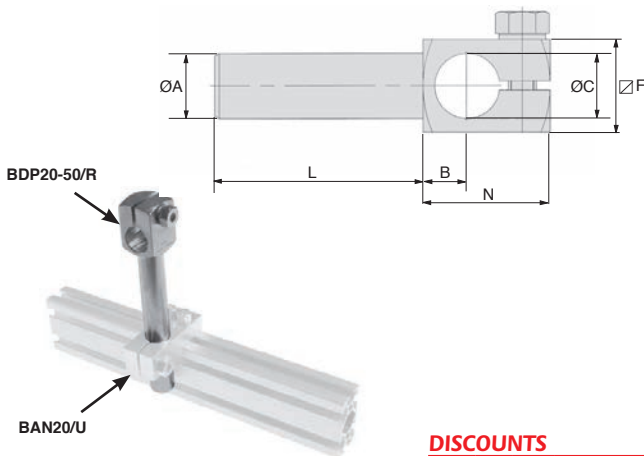

Typical application

### DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%	On request	

Part number	ØA	B	ØC	L	∅F	N	Weight (g)	Price each 1 to 9
BDP20-50/R	20	15	20	50	25	35	61	36,48 €
BDP20-100/R	20	15	20	100	25	35	80	44,62 €
BDP20-150/R	20	15	20	150	25	35	95	46,82 €
BDP30-200/R	30	17	30	200	35	42	95	57,49 €

Dimensions in mm

## Our other products



 
LQT

Mechanical catch,  
Quick closing catch



OPFL\_OPFM

Numerical counter  
accessories,  
Operating knob



MR\_MMR

Metric section rack,  
Steel



HS

Hexagonal spacer,  
Stainless steel 303



SVG

Adjustable latch  
clamp with strike  
plate, Stroke from  
118mm to 130,5mm



PR40

Articulated foot Ø40,  
Ø 40



 
PRF\_BV

Screw block, Panel  
addition and fastening



HTD5M\_09

HTD Heavy duty  
timing pulley, HTD5  
Steel



MAC

Carabiner DIN5299  
steel, Steel



VBFP

Small 6 lobe threaded  
handle - female,  
Duroplast - Stainless



BOXKK

Boxed set of  
DIN6885A keys,  
Boxed set - Steel or



HTD5M\_15

HTD Heavy duty  
timing pulley, HTD5  
Aluminium

## Complementary products



BDP1R

Adjustable support  
arm, Single clamp



BDP2R

Adjustable support  
arm, Increased grip