


- **Universal support arm**
- **Material :**
Aluminium with steel screws

Advantages

- **Reliable operation**
- **Flexible mounting**

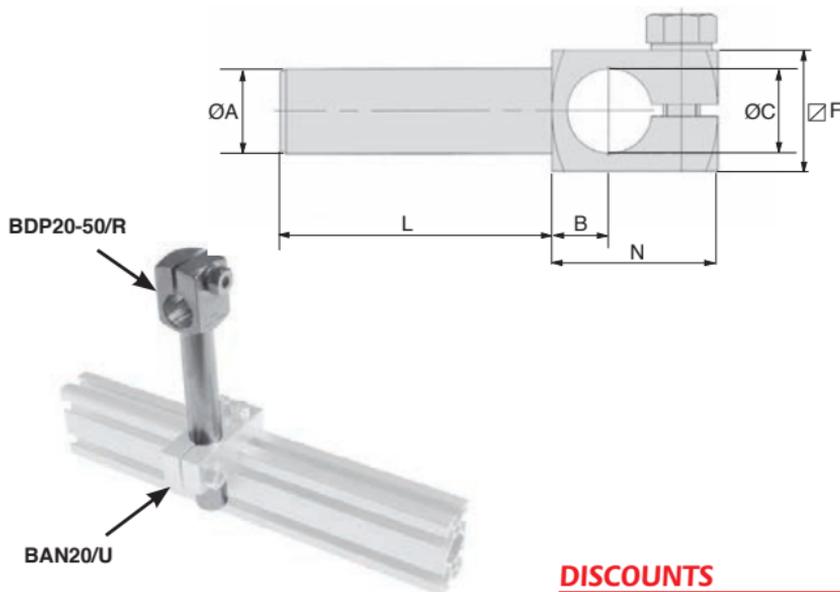

Typical application

DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%	On request	

Part number	ØA	B	ØC	L	∅F	N	Weight (g)	Price each 1 to 9
BDP20-50/R	20	15	20	50	25	35	61	36,48 €
BDP20-100/R	20	15	20	100	25	35	80	44,62 €
BDP20-150/R	20	15	20	150	25	35	95	46,82 €
BDP30-200/R	30	17	30	200	35	42	95	57,49 €

Dimensions in mm

Our other products



BLH50

Right angled gearbox,
from 7.70 to 20 Nm



PF30NM

Worm and wheel gear
reducer, up to 8.8 Nm



HS

Hexagonal spacer,
Stainless steel 303



CHAB

Hinge with stop,
Hinge



M1

Worm and wheel set,
Hardened steel



AT5-25ECO

AT type timing pulley,
Economy range - AT5
aluminium



BMM

Knurled knob - male,
Knurled



F7-SF-SM

Multifunction display,
Right angled
mounting bracket



AZY

Cylindrical elasto
mount, Steel



BLH60

Right angled gearbox,
from 19 to 70 Nm



PRF_BV

Screw block, Panel
addition and fastening



TBE12

Economic mini-table
with trapezoidal
leadscrew, 2kg

Complementary products



BDP1R

Adjustable support
arm, Single clamp



BDP2R

Adjustable support
arm, Increased grip