


- **Universal support arm**
- **Material :**  
Aluminium with steel screws

### Advantages

- **Reliable operation**
- **Flexible mounting**

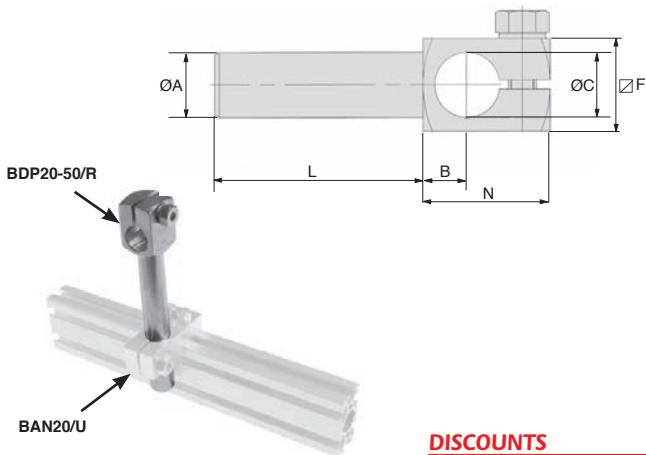

Typical application

### DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%	On request	

Part number	ØA	B	ØC	L	∅F	N	Weight (g)	Price each 1 to 9
BDP20-50/R	20	15	20	50	25	35	61	36,48 €
BDP20-100/R	20	15	20	100	25	35	80	44,62 €
BDP20-150/R	20	15	20	150	25	35	95	46,82 €
BDP30-200/R	30	17	30	200	35	42	95	57,49 €

Dimensions in mm

## Our other products



SH3  
Parallel axis helical gear, Steel 20NCD2



PLM-20SC  
Cylindrical magnet, Cylindrical magnet



AC  
Strike for toggle latch, 15mm



GTC  
Belt tensioner, For standard applications



NSB  
Standard linear bearing housing, Closed - Long



EHD16  
Internal epicyclic servo reducers, from 210 to 380 Nm



BPHF  
Ball transfer unit push fit, Heavy



DOG258  
Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



IBJ  
180° ball and socket joints, Steel



NDS20  
Double cross clamp, Crossed



CHAu  
Screwed hinge, 270°



CAP881  
Side flexing slim slat top chain stainless steel, Narrow range 881

## Complementary products



BDP1R  
Adjustable support arm, Single clamp



BDP2R  
Adjustable support arm, Increased grip