

Star shaped **anti-static** handle

BEAS Prevents occurrence of electrostatic spark

- **Eliminates electric charges**

- **Materials:**

Thermoplastic, black graphic finish

Thread - 5.8 steel



- Similar to DIN6336

Advantages

- These products can be used for discharging electrostatic charges in areas classified as ESD Protected Areas (EPA) in accordance with DIN EN61340-5-1

- For clear, unambiguous identification, the yellow ESD logo is printed of the side of the handle

NEW!

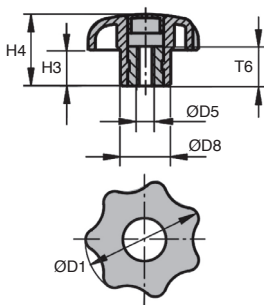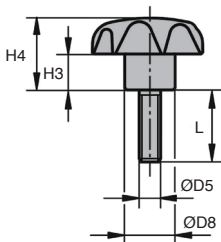

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD1	ØD5	ØD8	H3	H4	T6	L	Stock*	Price each 1 to 9
Female									
BEAS-8	40	M8	18	13	25	14	-	✓	2,90 €
Male									
BEAS-8-25	40	M8	18	13	25	-	25	New	4,12 €

*Depending on availability - Dimensions in mm

Our other products



TPEpbd

Castor for aluminium profile, Swivel with brake



EAR

Bearing locknut, Self locking locknut - nylon lock washer



M0

Worm and wheel set, Non hardened steel




CHML50

Worm and wheel gear reducer, up to 107 Nm - Integrated torque limiter



PAMF100EB

 Articulated foot with sheet metal base Ø100, Articulated foot



PTR

Idler chain sprocket, For standard sprocket applications



UCFL PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



DFG

Flat suction cup, silicon



LFM2

Steel leadscrew, Medium carbon steel - 2 threads




EP7

Electronic digital position indicator, 5 numbers



BAG-MISS

Split shaft collar with clamp lever, Stainless steel

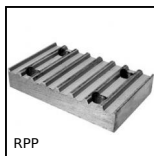

RPP

Connecting plate for RPP type timing belts, RPP8

Complementary products



PAS

Pull handle, Reinforced PA thermoplastic



EMAS

Antistatic knurled nut, Antistatic



PDM_PDV

Detectable plastic palm grip, by metal detectors



PDM_PDV

Detectable plastic palm grip, by metal detectors