

Star shaped **anti-static** handle

BEAS Prevents occurrence of electrostatic spark

- **Eliminates electric charges**

- **Materials:**

Thermoplastic, black graphic finish

Thread - 5.8 steel




- Similar to DIN6336

Advantages

- These products can be used for discharging electrostatic charges in areas classified as ESD Protected Areas (EPA) in accordance with DIN EN61340-5-1

- For clear, unambiguous identification, the yellow ESD logo is printed of the side of the handle

NEW!

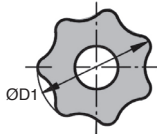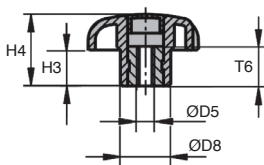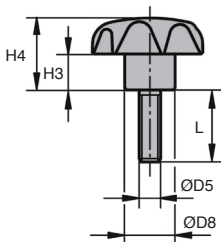

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request


Part number	ØD1	ØD5	ØD8	H3	H4	T6	L	Stock*	Price each 1 to 9
Female									
BEAS-8	40	M8	18	13	25	14	-	✓	2,90 €
Male									
BEAS-8-25	40	M8	18	13	25	-	25	New	4,12 €

*Depending on availability - Dimensions in mm

Our other products



 CM_CO
Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



MF
Shock Absorber
-universal flange,
Universal fixing



BWU
Compact precision
slide, from 1510 N to
10500 N



BLHB50
Right angled gearbox,
bored shafts, up to 30
Nm



CDGamme
Compression spring
DIN2095, DIN 2095



HLA28
Right angle spiro
bevel gearbox, Up to
182Nm




WS16
Drylin® W rail, Rail



LRR
Catch-plate for latch,
Catch-plate



 BABam
Self-locking ball pin
lifting ring for
threaded hole, Self-



AWMP
Aluminium shaft for
linear guide,
Aluminium



MBF
Threaded blocking
clamp, Threaded
locking clamp



MHXred
Reducing sleeve
male/female,
Hexagonal - steel

Complementary products



PAS
Pull handle,
Reinforced PA
thermoplastic



EMAS
Antistatic knurled nut,
Antistatic



PDM_PDV
Detectable plastic
palm grip, by metal
detectors



PDM_PDV
Detectable plastic
palm grip, by metal
detectors