

Star shaped **anti-static** handle

BEAS Prevents occurrence of electrostatic spark

- **Eliminates electric charges**

- **Materials:**

Thermoplastic, black graphic finish

Thread - 5.8 steel



- Similar to DIN6336

Advantages

- These products can be used for discharging electrostatic charges in areas classified as ESD Protected Areas (EPA) in accordance with DIN EN61340-5-1

- For clear, unambiguous identification, the yellow ESD logo is printed of the side of the handle

NEW!

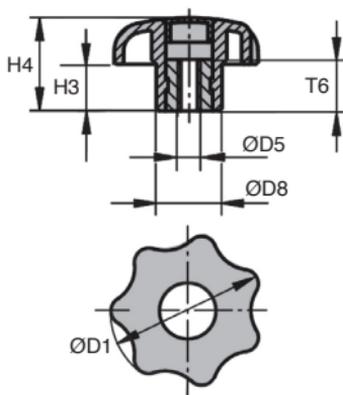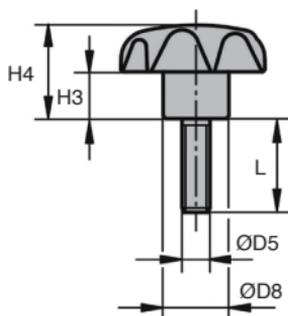

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD1	ØD5	ØD8	H3	H4	T6	L	Stock*	Price each 1 to 9
Female									
BEAS-8	40	M8	18	13	25	14	-	✓	2,90 €
Male									
BEAS-8-25	40	M8	18	13	25	-	25	New	4,12 €

*Depending on availability - Dimensions in mm

Our other products



BSM

Spring plunger with internal hexagonal socket, steel body and pin



MDR

Dee shackle with eye bolt, Steel



DER63

Stainless steel AC asynchronous motor
0.18 kW, 0.18kW



NT62

Spur gear coaxial gearbox, from 6 to 18 Nm - Inline




APBC

Circular rod, Round rod



CHAFR-MINI

Miniature friction hinge, Friction

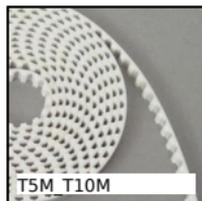


T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



SBF

Sealed flange bearing unit for Food Industry, cover

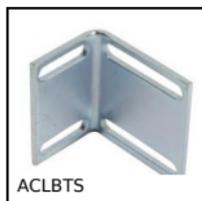

ACLBTS

Closing system for aluminium profile, 90°



PTA150

Articulated levelling foot, pressed base



R203

Die spring ISO10243, Light



PW_PWG05

Worm - precision range, Steel

Complementary products



BEAB

Knob star grip antibacterial, Star, anti-bacterial



PDM_PD V

Detectable plastic palm grip, by metal detectors



PDM_PD V

Detectable plastic palm grip, by metal detectors



PDM_PD V

Detectable plastic palm grip, blue thermoplastic