

Star shaped **anti-static** handle

BEAS Prevents occurrence of electrostatic spark

- **Eliminates electric charges**

- **Materials:**

Thermoplastic, black graphic finish

Thread - 5.8 steel




- Similar to DIN6336

Advantages

- These products can be used for discharging electrostatic charges in areas classified as ESD Protected Areas (EPA) in accordance with DIN EN61340-5-1

- For clear, unambiguous identification, the yellow ESD logo is printed of the side of the handle

NEW!

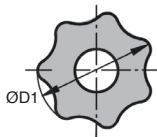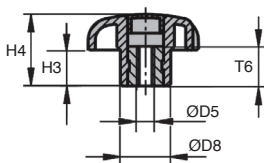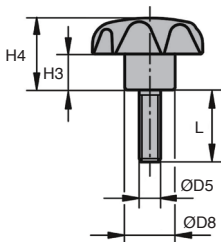

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD1	ØD5	ØD8	H3	H4	T6	L	Stock*	Price each 1 to 9
Female									
BEAS-8	40	M8	18	13	25	14	-	✓	2,90 €
Male									
BEAS-8-25	40	M8	18	13	25	-	25	New	4,12 €

*Depending on availability - Dimensions in mm

Our other products



PGM86-M5
Pull handle,
Thermoplastic



AXTR
Axle for tensioner
pulley, Shaft



PMC48_M8
Anti-vibration
machine mount, Oval
base plate



PW_PWG15
Wheel - precision
range, Bronze



G0
Steel spur gear, Steel
20NCD2



J65
Spur gear coaxial
gearbox, from 0.80 to
2.95 Nm - In-line



PCATherm
Pull handle,
Thermoplastic



R203
Die spring ISO10243,
Light



SLV
Vertical toggle clamp,
Vertical Lever Clamp -



BCFH
Mushroom headed
button Hygienic



RFV50
Stainless steel worm
and wheel gearbox,



BL15
Right angled gearbox,
from 1.10 to 6 Nm

Complementary products



BEAB
Knob star grip
antibacterial, Star,
anti-bacterial



PDM_PDV
Detectable plastic
palm grip, by metal
detectors



PDM_PDV
Detectable plastic
palm grip, by metal
detectors



PDM_PDV
Detectable plastic
palm grip, blue
thermoplastic