



Hitch pin



Zinc plated steel

BETA

- Low cost clip
- Made from zinc plated steel
- Supplied by the packet

Advantages

- Manual assembly/disassembly

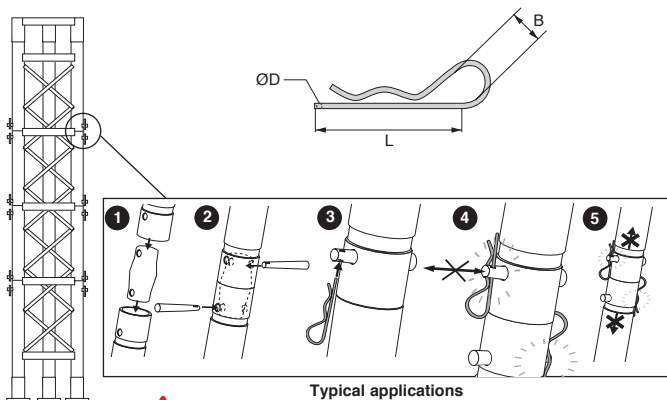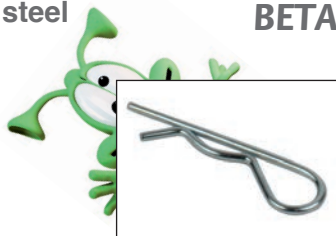

Typical applications



DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	B	For shaft	Weight per 100 (kg)	Quantity per pack	Stock*	Price each 1 to 4
BETA-2/B	2	53	12	9-11	0,5	100	✓	7,35 €
BETA-2.5/B	2,5	52	10	11-13	0,6	100	✓	9,22 €
BETA-3/B	3	66	15	13-17	0,9	100	✓	11,86 €
BETA-4/B	4	83	22	17-20	2,3	100	✓	22,74 €
BETA-4.5/B	4,5	68	24	20-23	2,5	100	-	30,21 €
BETA-5/B	5	100	23	23-26	3,9	100	-	38,65 €
BETA-6/B	6	105	26	26-30	6,0	50	✓	27,00 €
BETA-7/B	7	125	26	30-34	9,1	25	✓	37,77 €
BETA-8/B	8	142	29	34-45	13,6	25	-	47,25 €

Dimensions in mm

Our other products



PPC55
Pad eye on mounting
plate squarred,
Stainless steel



BAG55
Stainless steel
Clamping collar,
Stainless steel



CLG1
Moulded plastic spur
gear, Moulded plastic
(nylon)



ACA
Steel splined shaft,
Steel



SSG1_304L
Stainless steel spur
gear, Stainless steel
304L



GCH
Linear ball slide -
Stainless steel balls,
Chariot - from 514 N
to 1...



PRF-GUM
Aluminium profile
anodising polisher,
Polishing block



BABT
Hardened Stainless
steel ball pin,
Hardened stainless
steel



PCF4
Conical flexible
mount, Square base
plate



CHAM5270SS
Marine hinge for
welding/screw
mounting, Marine



BOX-CS55
Hose clamp, Box set
of stainless steel hose
clamps



SSE
Stainless steel
spherical bearing,
Stainless steel / PTFE

Complementary products