



Hitch pin



Zinc plated steel

BETA

- Low cost clip
- Made from zinc plated steel
- Supplied by the packet

Advantages

- Manual assembly/disassembly

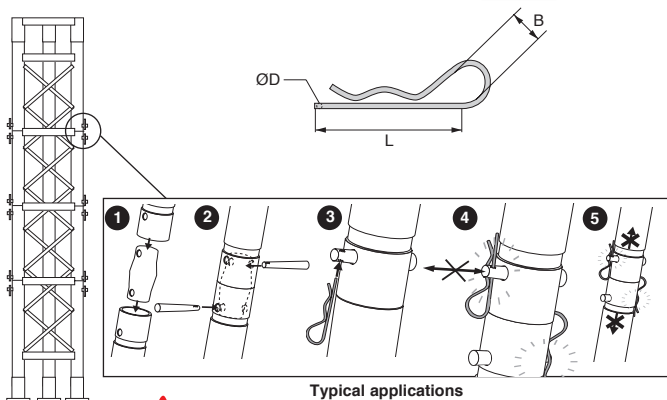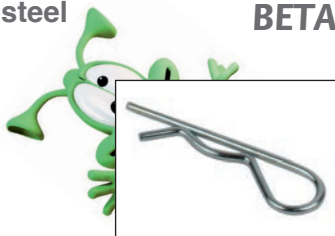

Typical applications



DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	B	For shaft	Weight per 100 (kg)	Quantity per pack	Stock*	Price each 1 to 4
BETA-2/B	2	53	12	9-11	0,5	100	✓	7,35 €
BETA-2.5/B	2,5	52	10	11-13	0,6	100	✓	9,22 €
BETA-3/B	3	66	15	13-17	0,9	100	✓	11,86 €
BETA-4/B	4	83	22	17-20	2,3	100	✓	22,74 €
BETA-4.5/B	4,5	68	24	20-23	2,5	100	-	30,21 €
BETA-5/B	5	100	23	23-26	3,9	100	-	38,65 €
BETA-6/B	6	105	26	26-30	6,0	50	✓	27,00 €
BETA-7/B	7	125	26	30-34	9,1	25	✓	37,77 €
BETA-8/B	8	142	29	34-45	13,6	25	-	47,25 €

Dimensions in mm

Our other products



EKN
Bellows coupling
Gerwah®, from 0.5 to
12Nm



GPB55
Threaded spherical
knob, Aluminium



R203
Die spring ISO10243,
Light



VELprf
Clip-on base for hook-
and-loop strip,
Polyamide



CHTRP
Single and dual
output gearboxes, Up
to 87,3 Nm



ZHG5
Plastic spur gear,
Machined plastic
(delrin)



FF40
Offset spur gear
reducer, from 59 to
210 Nm



CHA_GC_14SS
Stainless steel garnet
hinge, To screw



LFM
Steel leadscrew,
Medium carbon steel -



KBS_UU
Stainless steel closed
precision linear



UCP
Cast iron pillow block
bearing, Cast iron



PW_PWG25
Worm - precision
range, Stainless steel

Complementary products