



Hitch pin



Zinc plated steel

BETA

- Low cost clip
- Made from zinc plated steel
- Supplied by the packet

Advantages

- Manual assembly/disassembly

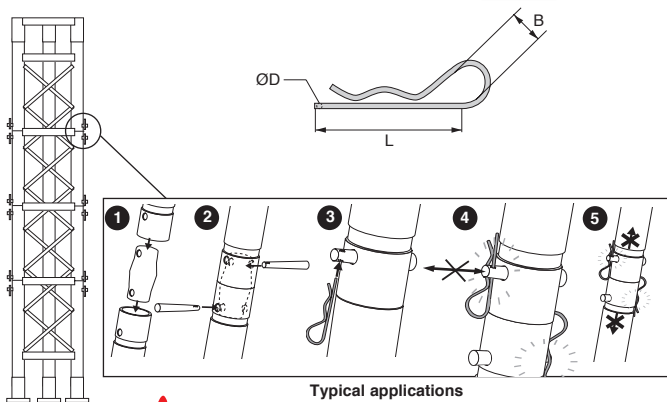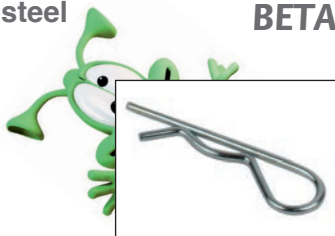

Typical applications



DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	B	For shaft	Weight per 100 (kg)	Quantity per pack	Stock*	Price each 1 to 4
BETA-2/B	2	53	12	9-11	0,5	100	✓	7,35 €
BETA-2.5/B	2,5	52	10	11-13	0,6	100	✓	9,22 €
BETA-3/B	3	66	15	13-17	0,9	100	✓	11,86 €
BETA-4/B	4	83	22	17-20	2,3	100	✓	22,74 €
BETA-4.5/B	4,5	68	24	20-23	2,5	100	-	30,21 €
BETA-5/B	5	100	23	23-26	3,9	100	-	38,65 €
BETA-6/B	6	105	26	26-30	6,0	50	✓	27,00 €
BETA-7/B	7	125	26	30-34	9,1	25	✓	37,77 €
BETA-8/B	8	142	29	34-45	13,6	25	-	47,25 €

Dimensions in mm

Our other products



DER63

Stainless steel AC asynchronous motor
0.18 kW, 0.18kW



CMAss

Eye bolt stainless steel, Stainless steel



H2

Crossed helical gear crossed axis at 90°, Steel 20NCD2



GLB

Small 6 lobe female handle, Technopolymer - Brass



PM3

Worm and wheel set, Bronze



ZB

Shaft for linear guides, Hardened ground stainless steel



MHMEP

Arm with rotating handle, Prebored



M1

Worm and wheel set, Hardened steel



RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide



STL

Guidance brush - Rail, Rail



BOXdh

Boxed set of cylindrical dowel pins DIN6325, Boxed set - Solid DIN 6...



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter

Complementary products