

Hitch pin




BETA

Zinc plated steel

- Low cost clip
- Made from zinc plated steel
- Supplied by the packet

Advantages

- Manual assembly/disassembly

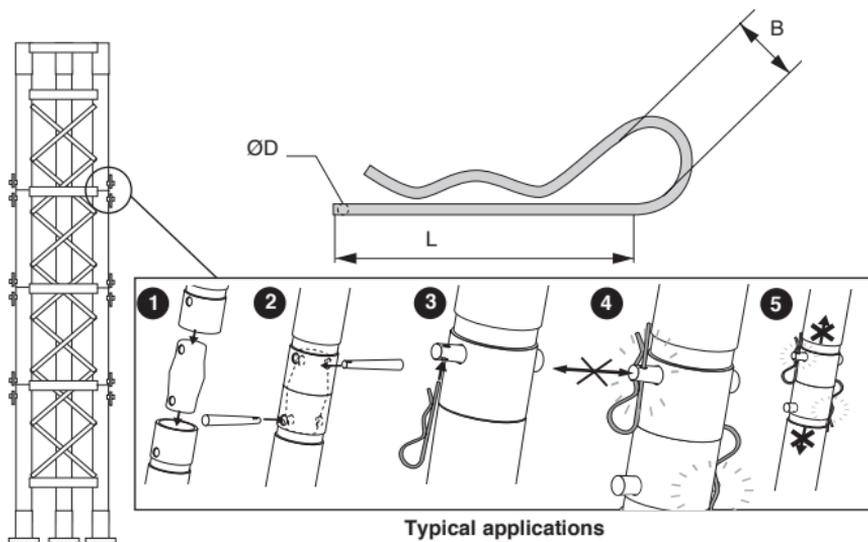

Typical applications

DISCOUNTS

Qty	1+	5+	10+	21+
Disc. List	-10%	-20%	On request	

Part number	ØD	L	B	For shaft	Weight per 100 (kg)	Quantity per pack	Stock*	Price each 1 to 4
BETA-2/B	2	53	12	9-11	0,5	100	✓	8,01 €
BETA-2.5/B	2,5	52	10	11-13	0,6	100	✓	10,06 €
BETA-3/B	3	66	15	13-17	0,9	100	✓	12,95 €
BETA-4/B	4	83	22	17-20	2,3	100	✓	24,84 €
BETA-4.5/B	4,5	68	24	20-23	2,5	100	✓	33,03 €
BETA-5/B	5	100	23	23-26	3,9	100	✓	42,28 €
BETA-6/B	6	105	26	26-30	6,0	50	✓	29,50 €
BETA-7/B	7	125	26	30-34	9,1	25	-	41,30 €
BETA-8/B	8	142	29	34-45	13,6	25	✓	51,68 €

*Depending on availability - Dimensions in mm


- Low cost clip
- Made from stainless steel AISI 304
- Supplied by the packet

Advantages

- Manual assembly/disassembly



stainless steel

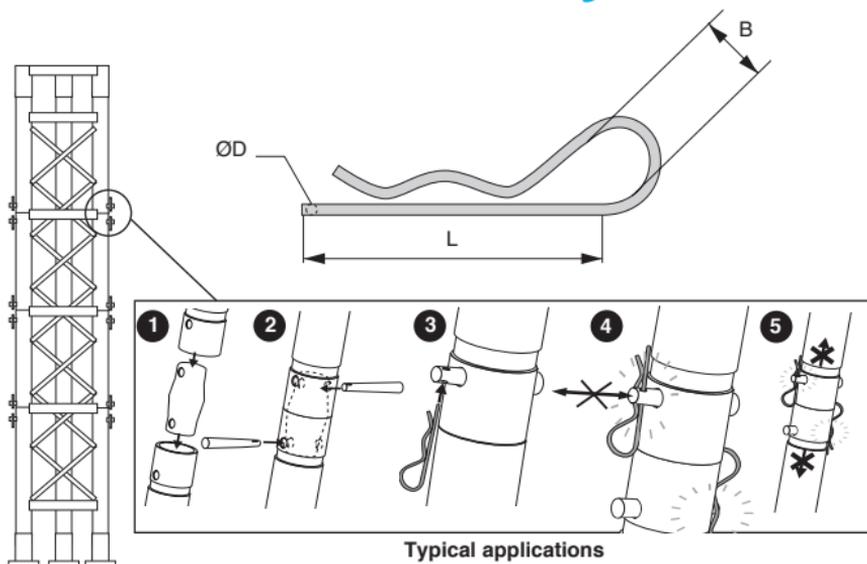

Typical applications


DISCOUNTS

Qty	1+	5+	10+	15+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	B	Weight per 100 (kg)	Quantity per pack	Price each 1 to 4
BETA-2/SS/B	2	53	12	0,32	100	35,11 €
BETA-3/SS/B	3	66	15	0,88	50	31,33 €
BETA-4/SS/B	4	83	22	1,49	25	32,09 €
BETA-5/SS/B	5	100	23	3,62	20	43,71 €
BETA-6/SS/B	6	105	26	5,56	10	34,21 €

*Depending on availability - Dimensions in mm

Our other products

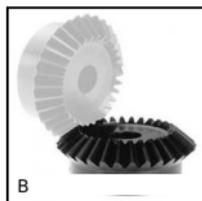

B
Steel bevel gear, 1:1



CHA35
Hinge for aluminium profile, Hinge



VPR
Wing screw Hygienic Usit®, Stainless steel



CHB
Worm and wheel gear reducer, up to 22 Nm



LC
Friction clutch, 190 to 1800 Nm



UGCG
Actuator guide kit, Long housing



FHCSS
Countersunk screw, Stainless steel A2 - DIN 7991



CHA60
Rectangular hinge, drilled or countersunk, Rectangular, drilled or C...



PRF_BV
Screw block, Panel addition and fastening



GSI_A
Gas control screw for gas spring, Gas



QN
Single row cylindrical roller bearing, Free



DOMI120
Connecting kits, XZ linking kit

Complementary products