
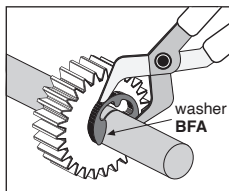



- Conforms to DIN 6799
- Stainless steel

### Advantages

- Can be fitted to a smooth shaft or in a groove (preferred)
- Can either be fitted axially or radially
- Easily removed using a screwdriver

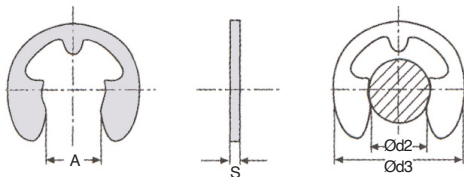

Typical application

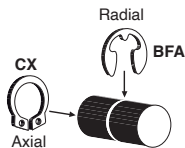

### DISCOUNTS

Qty	1+	6+	11+
Disc	List	-10%	On request

Part number	Ød2	Shaft Ø	Ød3 max	A	S	Quantity per box	Stock*	Price each 1 to 5
BFA-1.2/B	1,2	1,4 - 2,0	3,25	1,01	0,3	1000	✓	28,63 €
BFA-1.5/B	1,5	2,0 - 2,5	4,25	1,28	0,4	1000	✓	30,34 €
BFA-1.9/B	1,9	2,5 - 3,0	4,80	1,61	0,5	1000	✓	32,37 €
BFA-2.3/B	2,3	3,0 - 4,0	6,30	1,94	0,6	1000	✓	35,44 €
BFA-3.2/B	3,2	4,0 - 5,0	7,30	2,70	0,6	1000	✓	41,58 €
BFA-4/B	4,0	5,0 - 7,0	9,30	3,34	0,7	1000	✓	43,98 €
BFA-5/B	5,0	6,0 - 8,0	11,30	4,11	0,7	1000	✓	63,06 €
BFA-6/B	6,0	7,0 - 9,0	12,30	5,26	0,7	1000	✓	71,60 €
BFA-7/B	7,0	8,0 - 11,0	14,30	5,84	0,9	500	✓	48,58 €
BFA-8/B	8,0	9,0 - 12,0	16,30	6,52	1,0	500	✓	55,06 €
BFA-9/B	9,0	10,0 - 14,0	18,80	7,63	1,1	500	✓	77,06 €
BFA-10/B	10,0	11,0 - 15,0	20,40	8,32	1,2	500	✓	92,74 €
BFA-12/B	12,0	13,0 - 18,0	23,40	10,45	1,3	200	✓	54,68 €
BFA-15/B	15,0	16,0 - 24,0	29,40	12,61	1,5	200	✓	103,71 €
BFA-19/B	19,0	20,0 - 31,0	37,60	15,92	1,75	100	-	123,17 €

\*Depending of availability - Dimensions in mm

## Our other products




PCLA\_M

Technopolymer clamping lever - female, Plastic



IN2

 Internal gear, Steel 20NCD2



H1

Crossed helical gear  
crossed axis at 90°,  
Machined plastic  
(delrin)



SLS

Bearing block for  
leadscrew, Floating  
Drylin® bearing block



 
Q3

Double row angular  
contact ball bearing,  
Angular contact -  
Steel



PLM-SC

Magnetic stud with  
threaded hole, With  
threaded hole



IN1

Internal gear,  
Machined plastic  
(delrin)



AT10courroie

AT type timing belt,  
AT10 Steel cored  
polyurethane




PGT

Sliding profile, Sliding  
panel support




NT92

 Spur gear coaxial  
gearbox, from 15 to



TBL

 
Mini leadscrew table  
with metric thread,



PRF\_CHA\_D

Hinge and joint, Lift-  
off hinge

## Complementary products

 

CXS

External circlip  
DIN471, external DIN  
471



CYS

Internal circlip  
DIN472, internal DIN  
472



PAL

Self locking counter  
nut, For axial locking