
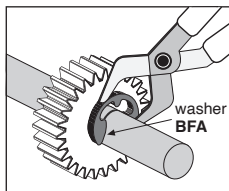



- Conforms to DIN 6799
- Stainless steel

Advantages

- Can be fitted to a smooth shaft or in a groove (preferred)
- Can either be fitted axially or radially
- Easily removed using a screwdriver

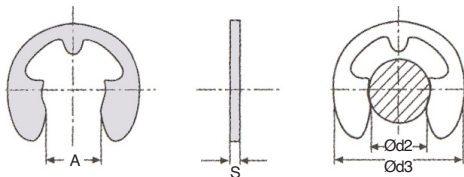

Typical application

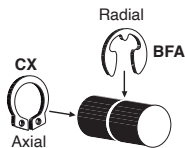

DISCOUNTS

Qty	1+	6+	11+
Disc	List	-10%	On request

Part number	Ød2	Shaft Ø	Ød3 max	A	S	Quantity per box	Stock*	Price each 1 to 5
BFA-1.2/B	1,2	1,4 - 2,0	3,25	1,01	0,3	1000	✓	28,63 €
BFA-1.5/B	1,5	2,0 - 2,5	4,25	1,28	0,4	1000	✓	30,34 €
BFA-1.9/B	1,9	2,5 - 3,0	4,80	1,61	0,5	1000	✓	32,37 €
BFA-2.3/B	2,3	3,0 - 4,0	6,30	1,94	0,6	1000	✓	35,44 €
BFA-3.2/B	3,2	4,0 - 5,0	7,30	2,70	0,6	1000	✓	41,58 €
BFA-4/B	4,0	5,0 - 7,0	9,30	3,34	0,7	1000	✓	43,98 €
BFA-5/B	5,0	6,0 - 8,0	11,30	4,11	0,7	1000	✓	63,06 €
BFA-6/B	6,0	7,0 - 9,0	12,30	5,26	0,7	1000	✓	71,60 €
BFA-7/B	7,0	8,0 - 11,0	14,30	5,84	0,9	500	✓	48,58 €
BFA-8/B	8,0	9,0 - 12,0	16,30	6,52	1,0	500	✓	55,06 €
BFA-9/B	9,0	10,0 - 14,0	18,80	7,63	1,1	500	✓	77,06 €
BFA-10/B	10,0	11,0 - 15,0	20,40	8,32	1,2	500	✓	92,74 €
BFA-12/B	12,0	13,0 - 18,0	23,40	10,45	1,3	200	✓	54,68 €
BFA-15/B	15,0	16,0 - 24,0	29,40	12,61	1,5	200	✓	103,71 €
BFA-19/B	19,0	20,0 - 31,0	37,60	15,92	1,75	100	-	123,17 €

*Depending of availability - Dimensions in mm

Our other products



RDS

Safety washer
Hygienic Usit®,
Stainless steel




HBM

Adjustment bushing
for half-rail guide,
Adjustment bushing



PITAss

Locking bolt, with T
handle

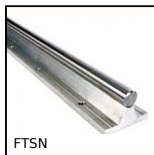

FTSN

Supported shaft for
linear guide, Steel
shaft / Aluminium
support



T10_21_AL

T type timing pulley,
Economy range - T10
aluminium




PSG25

Spur gear - precision
range, Stainless steel
303



CHAGC-AL

Screw-in garnet
hinge, Screw-on

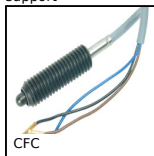

CFC

Spring loaded position
switch, Electric
contact



 
SUPTOOL

Installation tools for
clamping hub, For



ACL-PL

Joining plate for
aluminium profile,



RPPM

 
RPP type belt per
metre, RPP8 Steel



Q7


Angular contact ball
bearing, Steel

Complementary products



CXS

 External circlip
DIN471, external DIN
471



CYS

Internal circlip
DIN472, internal DIN
472



PAL

Self locking counter
nut, For axial locking