
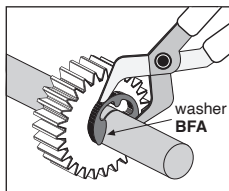



- Conforms to DIN 6799
- Stainless steel

Advantages

- Can be fitted to a smooth shaft or in a groove (preferred)
- Can either be fitted axially or radially
- Easily removed using a screwdriver

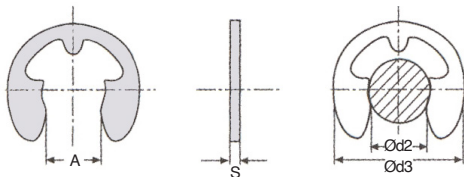

Typical application

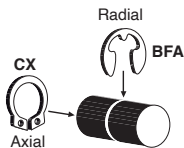

DISCOUNTS

Qty	1+	6+	11+
Disc	List	-10%	On request

Part number	Ød2	Shaft Ø	Ød3 max	A	S	Quantity per box	Stock*	Price each 1 to 5
BFA-1.2/B	1,2	1,4 - 2,0	3,25	1,01	0,3	1000	✓	28,63 €
BFA-1.5/B	1,5	2,0 - 2,5	4,25	1,28	0,4	1000	✓	30,34 €
BFA-1.9/B	1,9	2,5 - 3,0	4,80	1,61	0,5	1000	✓	32,37 €
BFA-2.3/B	2,3	3,0 - 4,0	6,30	1,94	0,6	1000	✓	35,44 €
BFA-3.2/B	3,2	4,0 - 5,0	7,30	2,70	0,6	1000	✓	41,58 €
BFA-4/B	4,0	5,0 - 7,0	9,30	3,34	0,7	1000	✓	43,98 €
BFA-5/B	5,0	6,0 - 8,0	11,30	4,11	0,7	1000	✓	63,06 €
BFA-6/B	6,0	7,0 - 9,0	12,30	5,26	0,7	1000	✓	71,60 €
BFA-7/B	7,0	8,0 - 11,0	14,30	5,84	0,9	500	✓	48,58 €
BFA-8/B	8,0	9,0 - 12,0	16,30	6,52	1,0	500	✓	55,06 €
BFA-9/B	9,0	10,0 - 14,0	18,80	7,63	1,1	500	✓	77,06 €
BFA-10/B	10,0	11,0 - 15,0	20,40	8,32	1,2	500	✓	92,74 €
BFA-12/B	12,0	13,0 - 18,0	23,40	10,45	1,3	200	✓	54,68 €
BFA-15/B	15,0	16,0 - 24,0	29,40	12,61	1,5	200	✓	103,71 €
BFA-19/B	19,0	20,0 - 31,0	37,60	15,92	1,75	100	-	123,17 €

*Depending of availability - Dimensions in mm

Our other products



 
Miniature cam follower, Miniature



Spur gear coaxial gearbox, from 20 to 68 Nm - Inline



Square hinge with riveted pin, not drilled, Square with riveted pin,...



Wear strip for slat top chain, L profile to be clipped



Progressive stop, Steel



Flat magnet, Flat magnet



Screwed hinge, 270°



Round guide, Round guide for conical profile



AT type timing belt per metre, AT5 Steel



Stainless steel splined shaft, Stainless steel

 


90° ball and socket joints DIN71802, Steel




Connecting plate for T type timing belts, T5

Complementary products



 External circlip DIN471, external DIN 471



Internal circlip DIN472, internal DIN 472



Self locking counter nut, For axial locking