
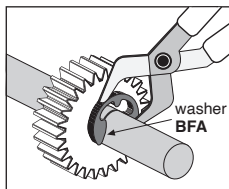



- Conforms to DIN 6799
- Stainless steel

Advantages

- Can be fitted to a smooth shaft or in a groove (preferred)
- Can either be fitted axially or radially
- Easily removed using a screwdriver

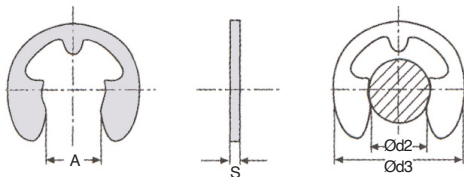

Typical application

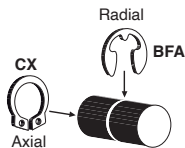

DISCOUNTS

Qty	1+	6+	11+
Disc	List	-10%	On request

Part number	Ød2	Shaft Ø	Ød3 max	A	S	Quantity per box	Stock*	Price each 1 to 5
BFA-1.2/B	1,2	1,4 - 2,0	3,25	1,01	0,3	1000	✓	28,63 €
BFA-1.5/B	1,5	2,0 - 2,5	4,25	1,28	0,4	1000	✓	30,34 €
BFA-1.9/B	1,9	2,5 - 3,0	4,80	1,61	0,5	1000	✓	32,37 €
BFA-2.3/B	2,3	3,0 - 4,0	6,30	1,94	0,6	1000	✓	35,44 €
BFA-3.2/B	3,2	4,0 - 5,0	7,30	2,70	0,6	1000	✓	41,58 €
BFA-4/B	4,0	5,0 - 7,0	9,30	3,34	0,7	1000	✓	43,98 €
BFA-5/B	5,0	6,0 - 8,0	11,30	4,11	0,7	1000	✓	63,06 €
BFA-6/B	6,0	7,0 - 9,0	12,30	5,26	0,7	1000	✓	71,60 €
BFA-7/B	7,0	8,0 - 11,0	14,30	5,84	0,9	500	✓	48,58 €
BFA-8/B	8,0	9,0 - 12,0	16,30	6,52	1,0	500	✓	55,06 €
BFA-9/B	9,0	10,0 - 14,0	18,80	7,63	1,1	500	✓	77,06 €
BFA-10/B	10,0	11,0 - 15,0	20,40	8,32	1,2	500	✓	92,74 €
BFA-12/B	12,0	13,0 - 18,0	23,40	10,45	1,3	200	✓	54,68 €
BFA-15/B	15,0	16,0 - 24,0	29,40	12,61	1,5	200	✓	103,71 €
BFA-19/B	19,0	20,0 - 31,0	37,60	15,92	1,75	100	-	123,17 €

*Depending of availability - Dimensions in mm

Our other products



PRF_PF
Anchoring bracket for aluminium profile,
Anchor



PTA50ssEB
Articulated foot with sheet metal base
Ø50, Articulated foot



UTKswcr
Utilittrak® 3 wheels carriage, Steel roller carriage



CHAL3
Piano hinge, Steel



RT70
Self-centering locking Assembly,
Medium/high torque



PRF-CHAR-POU
Tool holder for aluminium profile,
Moveable tool holder



LINK64
Synchronous AC Motor and- gearbox ,
from 1.3 to 6Nm



AC144
Strike for toggle latch,
22mm



T2
T type timing belt,
2.5 Steel cored



UCP_SS
Stainless steel pillow block bearing,




PCS37
Chain sprocket - steel,
9.525mm (DIN06B-1)




PM2
Worm and wheel set,
Non hardened steel

 Complementary products



 CXS
External circlip
DIN471, external DIN
471



CYS
Internal circlip
DIN472, internal DIN
472



PAL
Self locking counter
nut, For axial locking