



1 start, right or left hand thread

BFM BFMLH

- Right or left-hand thread
- Toleranced flange
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P

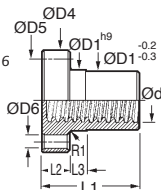

 Toleranced flange



Accessories

- LFM steel leadscrew or LSM stainless steel leadscrew

DISCOUNTS A

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

DISCOUNTS B

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Ød	ØD1	ØD4	ØD5	ØD6	L1	L2	L3	Stock*	Price each	
										1 to 9	20 to 39**
Right-hand thread											
BFM102	10 x 2	25	42	34	5	25	10	6	✓	A 30,87 €	A 18,52 €
BFM123	12 x 3	28	48	38	6	35	12	8	✓	A 44,84 €	A 26,91 €
BFM164	16 x 4	28	48	38	6	35	12	8	✓	A 44,96 €	A 26,91 €
BFM184	18 x 4	28	48	38	6	35	12	8	✓	A 44,96 €	A 26,98 €
BFM204	20 x 4	32	55	45	7	44	12	8	✓	A 66,29 €	A 26,98 €
BFM225	22 x 5	32	55	45	7	44	12	8	✓	A 66,83 €	A 39,78 €
BFM245	24 x 5	32	55	45	7	44	12	8	✓	A 62,46 €	A 37,47 €
BFM285	28 x 5	38	62	50	7	46	14	8	✓	A 85,58 €	A 51,35 €
BFM306	30 x 6	38	62	50	7	46	14	8	✓	A 85,92 €	A 51,55 €
BFM326	32 x 6	45	70	58	7	54	16	10	✓	A 129,73 €	A 77,84 €
BFM366	36 x 6	45	70	58	7	54	16	10	✓	B 69,99 €	B On request
BFM407	40 x 7	63	95	78	9	66	16	12	✓	B 131,38 €	B On request
BFM447	44 x 7	63	95	78	9	66	16	12	-	B 144,10 €	B On request
BFM508	50 x 8	72	110	90	11	75	18	14	✓	B 213,72 €	B On request
BFM609	60 x 9	88	130	110	13	90	20	16	-	B 350,81 €	B On request
BFM7010	70 x 10	95	140	120	13	105	22	17	-	B 497,88 €	B On request
Left-hand thread											
BFM102/LH	10 x 2	25	42	34	5	25	10	6	✓	A 34,99 €	A 20,99 €
BFM123/LH	12 x 3	28	48	38	6	35	12	8	✓	A 50,83 €	A 30,50 €
BFM164/LH	16 x 4	28	48	38	6	35	12	8	✓	A 50,93 €	A 30,50 €
BFM184/LH	18 x 4	28	48	38	6	35	12	8	✓	A 51,00 €	A 30,60 €
BFM204/LH	20 x 4	32	55	45	7	44	12	8	✓	A 69,71 €	A 41,83 €
BFM225/LH	22 x 5	32	55	45	7	44	12	8	✓	A 82,32 €	A 49,39 €
BFM245/LH	24 x 5	32	55	45	7	44	12	8	✓	A 67,98 €	A 40,79 €
BFM285/LH	28 x 5	38	62	50	7	46	14	8	✓	A 101,15 €	A 60,70 €
BFM306/LH	30 x 6	38	62	50	7	46	14	8	✓	A 90,89 €	A 54,50 €
BFM326/LH	32 x 6	45	70	58	7	54	16	10	-	A 144,72 €	A 86,83 €
BFM366/LH	36 x 6	45	70	58	7	54	16	10	✓	B 77,55 €	B On request
BFM407/LH	40 x 7	63	95	78	9	66	16	12	✓	B 134,03 €	B On request
BFM447/LH	44 x 7	63	95	78	9	66	16	12	-	B 150,46 €	B On request
BFM508/LH	50 x 8	72	110	90	11	75	18	14	-	B 230,75 €	B On request
BFM609/LH	60 x 9	88	130	110	13	90	20	16	-	B 380,05 €	B On request
BFM7010/LH	70 x 10	95	140	120	13	105	22	17	-	B 535,00 €	B On request

*Depending on availability - Dimensions in mm

** refer to discounts

Our other products



ESCON

Speed controller 5A accessories, USB cable for PC link



VRSSss

Male swivelling lifting rings stainless steel, Male swivelling - s...



HTD14M_55

HTD Heavy duty timing pulley, HTD14 Cast



BSM_LOK

Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



SVT_CH

Screwjack - pivot mounting, Pivoting bracket



 
TSM_T10M

T type timing belt per metre, T10 Steel cored polyurethane




DPAR_DKON

Progressive stop, Steel



PF45

 Worm and wheel gear reducer, up to 40 Nm



RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



BOXdhx

Boxed set of threaded dowel pins DIN7979D, Boxed set -



MPS

Hexagonal spacer, Stainless steel 303



PRF-P

Aluminium profile feet support, For feet or casters

Complementary products




LFM

Steel leadscrew, Medium carbon steel - 1 thread



LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread

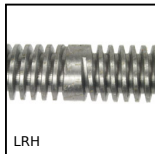

LRH

Bi-directional leadscrew, Bi-directional - 1 thread