



1 start, right or left hand thread

BFM BFMLH

- Right or left-hand thread
- Toleranced flange
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P

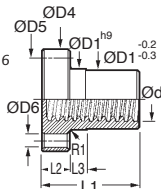

 Toleranced flange



Accessories

- LFM steel leadscrew or LSM stainless steel leadscrew

DISCOUNTS A

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

DISCOUNTS B

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Ød	ØD1	ØD4	ØD5	ØD6	L1	L2	L3	Stock*	Price each	
										1 to 9	20 to 39**
Right-hand thread											
BFM102	10 x 2	25	42	34	5	25	10	6	✓	A 30,87 €	A 18,52 €
BFM123	12 x 3	28	48	38	6	35	12	8	✓	A 44,84 €	A 26,91 €
BFM164	16 x 4	28	48	38	6	35	12	8	✓	A 44,96 €	A 26,91 €
BFM184	18 x 4	28	48	38	6	35	12	8	✓	A 44,96 €	A 26,98 €
BFM204	20 x 4	32	55	45	7	44	12	8	✓	A 66,29 €	A 26,98 €
BFM225	22 x 5	32	55	45	7	44	12	8	✓	A 66,83 €	A 39,78 €
BFM245	24 x 5	32	55	45	7	44	12	8	✓	A 62,46 €	A 37,47 €
BFM285	28 x 5	38	62	50	7	46	14	8	✓	A 85,58 €	A 51,35 €
BFM306	30 x 6	38	62	50	7	46	14	8	✓	A 85,92 €	A 51,55 €
BFM326	32 x 6	45	70	58	7	54	16	10	✓	A 129,73 €	A 77,84 €
BFM366	36 x 6	45	70	58	7	54	16	10	✓	B 69,99 €	B On request
BFM407	40 x 7	63	95	78	9	66	16	12	✓	B 131,38 €	B On request
BFM447	44 x 7	63	95	78	9	66	16	12	-	B 144,10 €	B On request
BFM508	50 x 8	72	110	90	11	75	18	14	✓	B 213,72 €	B On request
BFM609	60 x 9	88	130	110	13	90	20	16	-	B 350,81 €	B On request
BFM7010	70 x 10	95	140	120	13	105	22	17	-	B 497,88 €	B On request
Left-hand thread											
BFM102/LH	10 x 2	25	42	34	5	25	10	6	✓	A 34,99 €	A 20,99 €
BFM123/LH	12 x 3	28	48	38	6	35	12	8	✓	A 50,83 €	A 30,50 €
BFM164/LH	16 x 4	28	48	38	6	35	12	8	✓	A 50,93 €	A 30,50 €
BFM184/LH	18 x 4	28	48	38	6	35	12	8	✓	A 51,00 €	A 30,60 €
BFM204/LH	20 x 4	32	55	45	7	44	12	8	✓	A 69,71 €	A 41,83 €
BFM225/LH	22 x 5	32	55	45	7	44	12	8	✓	A 82,32 €	A 49,39 €
BFM245/LH	24 x 5	32	55	45	7	44	12	8	✓	A 67,98 €	A 40,79 €
BFM285/LH	28 x 5	38	62	50	7	46	14	8	✓	A 101,15 €	A 60,70 €
BFM306/LH	30 x 6	38	62	50	7	46	14	8	✓	A 90,89 €	A 54,50 €
BFM326/LH	32 x 6	45	70	58	7	54	16	10	-	A 144,72 €	A 86,83 €
BFM366/LH	36 x 6	45	70	58	7	54	16	10	✓	B 77,55 €	B On request
BFM407/LH	40 x 7	63	95	78	9	66	16	12	✓	B 134,03 €	B On request
BFM447/LH	44 x 7	63	95	78	9	66	16	12	-	B 150,46 €	B On request
BFM508/LH	50 x 8	72	110	90	11	75	18	14	-	B 230,75 €	B On request
BFM609/LH	60 x 9	88	130	110	13	90	20	16	-	B 380,05 €	B On request
BFM7010/LH	70 x 10	95	140	120	13	105	22	17	-	B 535,00 €	B On request

*Depending on availability - Dimensions in mm

** refer to discounts

Our other products



PRT-TO

iglidur® slewing ring,
With external teeth-
Iglidur®, aluminium &
S...



PSG35

Spur gear - precision
range, Stainless steel
316



RHTtcss

High Temperature
Castor, up to 200kg



BOX-CSss

Hose clamp, Box set
of stainless steel hose
clamps



T10-BAR

T type tooth bar
stock, T10



G-ECO

Eco range Spur gear,
Steel C45



MDB_MTB

Moulded plastic bevel
gear (nylon), 2:1



TBEBASE10

Economic mini-table
with trapezoidal
leadscrew, 1kg



PARF80

Pressed steel base
rigid foot, Swivelling -



M1

Worm and wheel set,
Hardened steel



BOX-TOR-MAX

Box set of Nitrile O-
rings in nitrile, 2.90 x



HG8-ECO

Eco range Spur gear,
Steel C45

Complementary products



 
LFM

Steel leadscrew,
Medium carbon steel -
1 thread



LSM

Stainless steel 316L
leadscrew, Stainless
steel - 1 thread



LRH

Bi-directional
leadscrew, Bi-
directional - 1 thread